

# E10423



## Female cordset

ADOAH042MSS0015A04

Article no longer available - archive entry



### Electrical data

Operating voltage [V] 10...30 DC

### Outputs

Electrical design PNP

### Operating conditions

Ambient temperature [°C] -25...90

Protection IP 67

### Mechanical data

Dimensions [mm] 27 x 15 x 39

Material TPU (urethane) transparent

Molded-body material TPU (urethane), transparent

Material nut brass, nickel-plated

### Displays / operating elements

Display Switching status 1 x LED, yellow

Power 1 x LED, green

### Remarks

Pack quantity 1 pcs.

# E10423



## Female cordset

ADOAH042MSS0015A04

### Electrical connection


Cable: 15 m, PUR / PVC, orange, Ø 5 mm; 4 x 0.25 mm<sup>2</sup> (32 x Ø 0.1 mm )

### Electrical connection - Socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU (urethane), transparent; Locking: brass, nickel-plated; Tightening torque: 0.5 Nm



### Connection

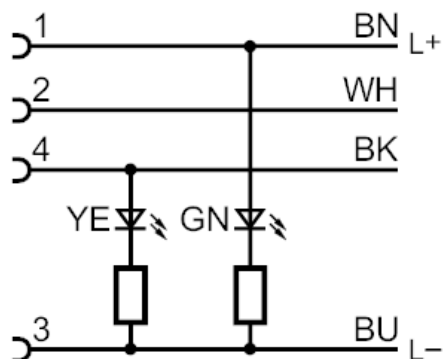

Core colors :  
BN = brown  
BK = black  
BU = blue  
WH = white