


E10426



Female cordset

ADOAH043MSS00,5E04

Article no longer available - archive entry

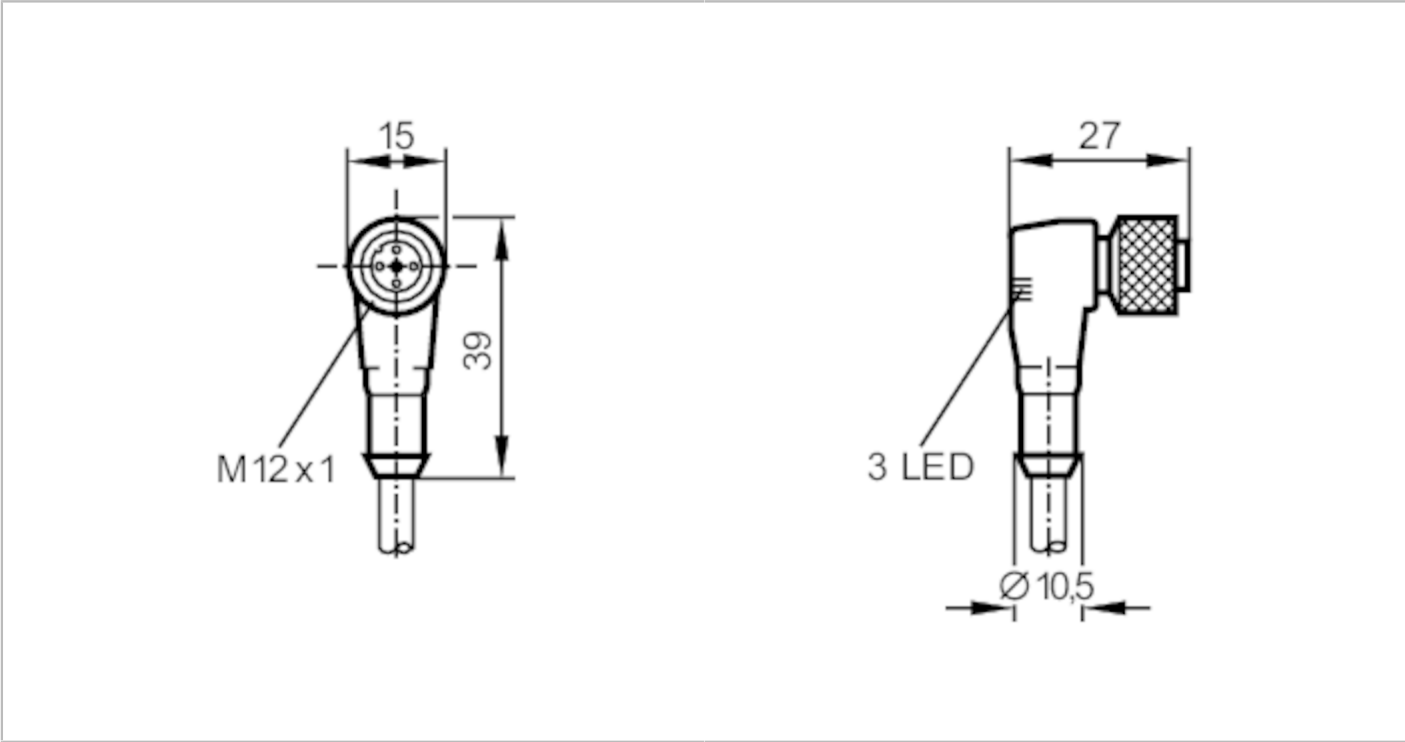

Electrical data		
Operating voltage	[M]	10...30 DC
Outputs		
Electrical design		PNP
Operating conditions		
Ambient temperature	[°C]	-25...70
Protection		IP 67
Mechanical data		
Dimensions	[mm]	27 x 15 x 39
Material		TPU (urethane) transparent
Molded-body material		TPU (urethane), transparent
Material nut		brass, nickel-plated
Displays / operating elements		
Display	Switching status	2 x LED, yellow
	Power	1 x LED, green
Remarks		
Pack quantity		1 pcs.

E10426



Female cordset

ADOAH043MSS00,5E04

Electrical connection


Cable: 0.5 m, PVC, orange, Ø 5 mm; 4 x 0.25 mm² (32 x Ø 0.1 mm)

Electrical connection - Socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU (urethane), transparent; Locking: brass, nickel-plated



Connection

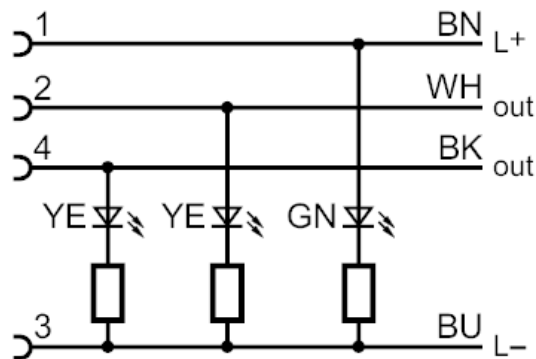

BN =	Core colors :
BK =	brown
BU =	black
WH =	blue
	white