


Male receptacle

ESTGH020MSS0,05E02 (PG13,5)

Article no longer available - archive entry

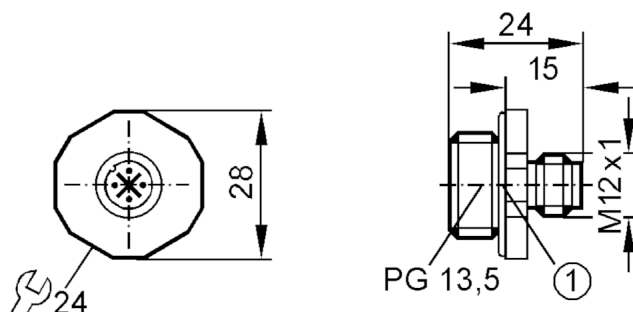

1 O-ring

Electrical data

Operating voltage	[V]	< 55 DC
-------------------	-----	---------

Operating conditions

Ambient temperature	[°C]	-40...85
---------------------	------	----------

Protection	IP 67
------------	-------

Mechanical data

Mounting thread	PG 13.5
-----------------	---------

Material	brass nickel-plated
----------	---------------------

Molded-body material	brass, nickel-plated
----------------------	----------------------

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection

Cable: 0.05 m, PVC; 2 x 0.34 mm²

Electrical connection - plug

Connector: 1 x M12; coding: A; Moulded body: brass, nickel-plated



E10436



Male receptacle

ESTGH020MSS0,05E02 (PG13,5)

Connection

1 BK

4 WH

BK = Core colors :
WH = black
white