

E10443




Connection cable

VDOGH040MSS00,6B04STGH040MSS

Article no longer available - archive entry

Alternative articles: EVC011
When selecting an alternative article and accessories please note that technical data may differ!

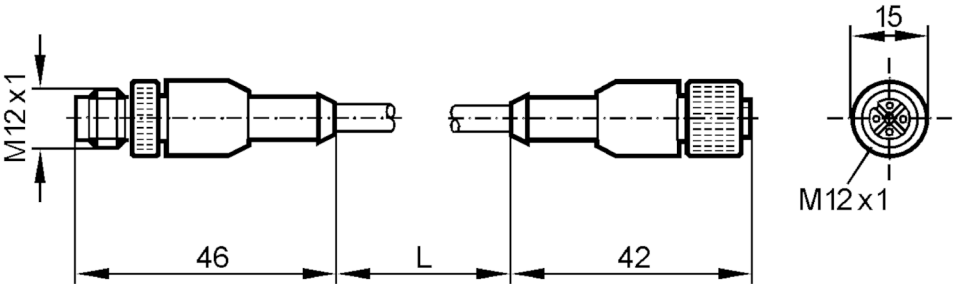

Electrical data

Operating voltage	[V]	10...30 DC
-------------------	-----	------------

Operating conditions

Ambient temperature	[°C]	-25...85
Protection		IP 67

Mechanical data

Material	TPU (urethane)
Molded-body material	TPU (urethane)
Material nut	brass, nickel-plated

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated



E10443




Connection cable

VDOGH040MSS00,6B04STGH040MSS

Electrical connection

Cable: 0.6 m, PUR / PVC; 4 x 0.34 mm² (128 x Ø 0.1 mm)

Connection

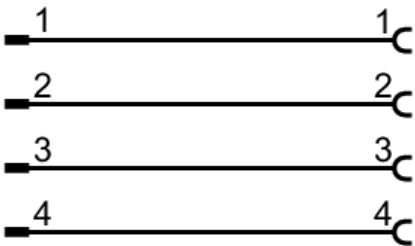

Electrical connection - Socket

Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated

