

E10445




Wiring block

ZDO6H057MSS0000-00STAM120MSS

Article no longer available - archive entry

Alternative articles: EBC006
When selecting an alternative article and accessories please note that technical data may differ!

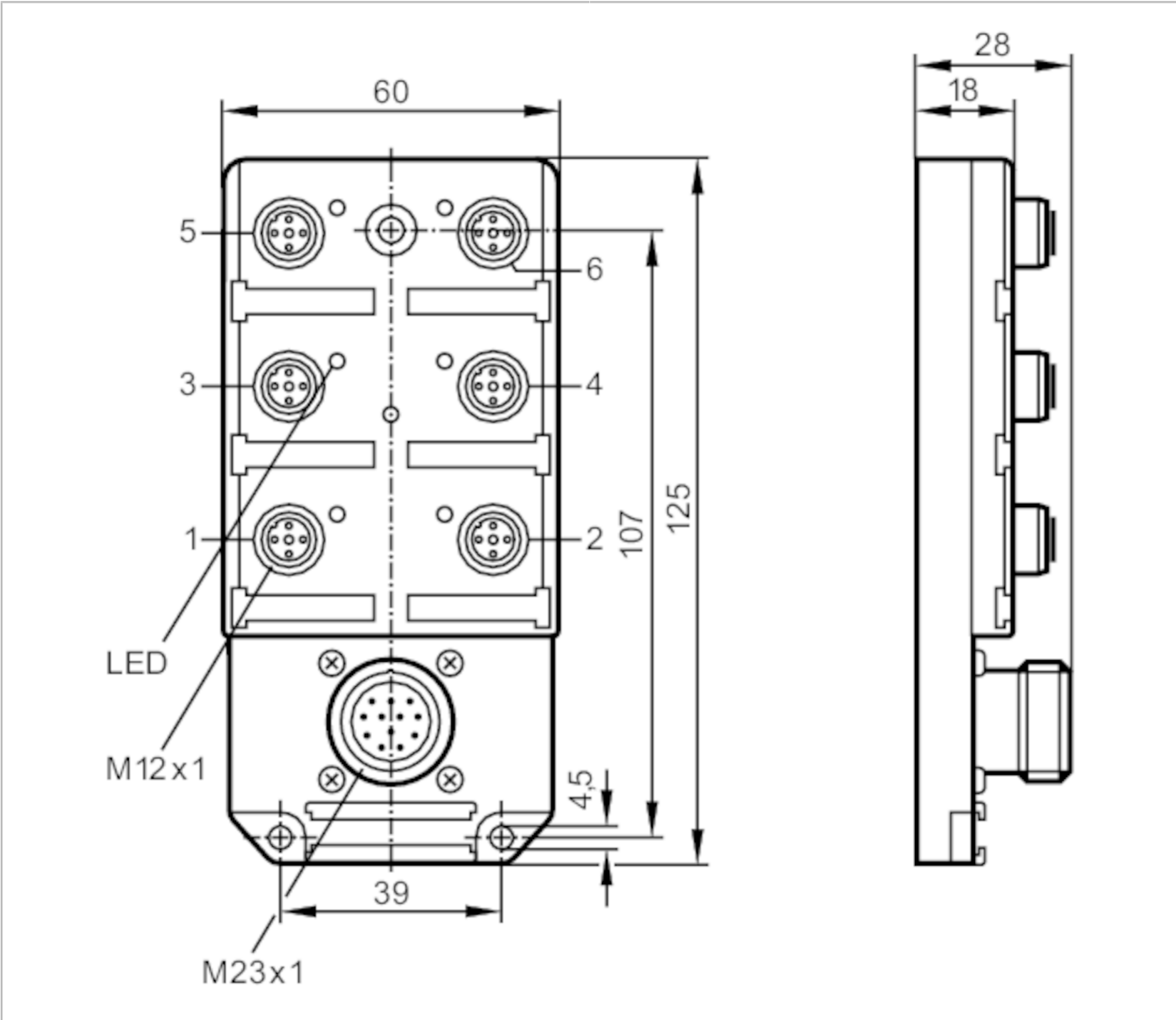

Application		
System		Free from silicone; gold-plated contacts
Free from silicone		yes
Electrical data		
Operating voltage	[V]	10...30 DC
Protection class		II
Max. current load per module/slot	[A]	4
Max. current load total	[A]	12

E10445




Wiring block

ZDO6H057MSS0000-00STAM120MSS


Operating conditions		
Ambient temperature	[°C]	-15...80
Protection		IP 67
Mechanical data		
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Number of ports splitter box		6
Connector type		M12
Displays / operating elements		
Display	Switching status	6 x LED, yellow
	Power	1 x LED, green
Remarks		
Pack quantity		1 pcs.

Electrical connection - Connection

Connector: 1 x M23; Moulded body: TPU (urethane); Contacts: gold-plated; Tightening torque: 0.5 Nm

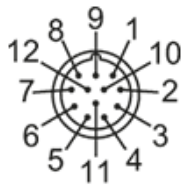

Connection

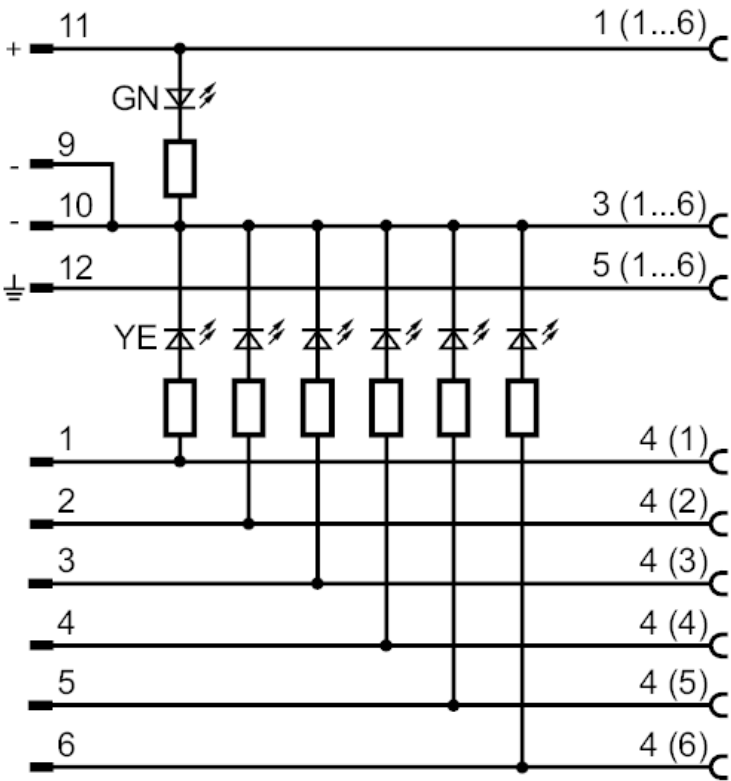

E10445



Wiring block

ZDO6H057MSS0000-00STAM120MSS

Electrical connection - slot

Connector: 6 x M12; coding: A; Moulded body: TPU (urethane); Contacts: gold-plated; Tightening torque: 0.5 Nm

