

E10452



Female cordset

ADOAH042VAS0015E03

Article no longer available - archive entry



Electrical data

Operating voltage [V] 10...30 DC

Outputs

Electrical design PNP

Operating conditions

Ambient temperature [°C] -25...90

Protection IP 67

Mechanical data

Material TPU (urethane) transparent
Molded-body material TPU (urethane), transparent
Material nut stainless steel (1.4404 / 316L)

Remarks

Pack quantity 1 pcs.

E10452



Female cordset

ADOAH042VAS0015E03

Electrical connection


Cable: 15 m, PVC, orange, Ø 5 mm; 3 x 0.34 mm²

Electrical connection - Socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU (urethane), transparent; Locking: stainless steel (1.4404 / 316L);
Tightening torque: 0.5 Nm



Connection

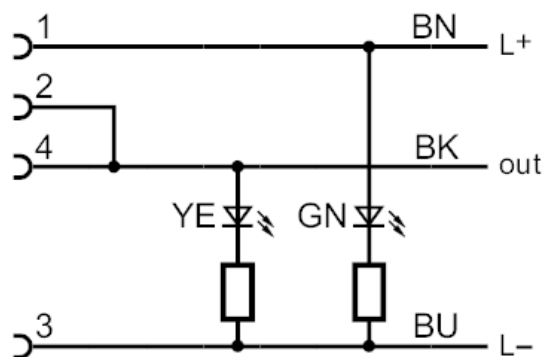

BK = black
BN = brown
BU = blue

Core colors :