

E10457



Connection cable

VDOGH042MSS00,3A04STGH040MSS

Article no longer available - archive entry



Electrical data

Operating voltage	[V]	10...30 DC
-------------------	-----	------------

Outputs

Electrical design	PNP
-------------------	-----

Operating conditions

Ambient temperature	[°C]	-25...90
---------------------	------	----------

Protection	IP 67
------------	-------

Mechanical data

Material	TPU (urethane)
----------	----------------

Molded-body material	TPU (urethane)
----------------------	----------------

Material nut	brass, nickel-plated
--------------	----------------------

Displays / operating elements


Display	Switching status	1 x LED, yellow
	Power	1 x LED, green

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated; Tightening torque: 0.5 Nm

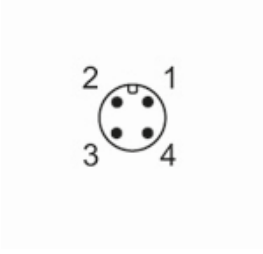

E10457



Connection cable

VDOGH042MSS00,3A04STGH040MSS

Electrical connection

Cable: 0.3 m, PUR / PVC; 4 x 0.25 mm² (32 x Ø 0.1 mm)

Connection



Core colors :
BK = black
BN = brown
BU = blue
WH = white

Electrical connection - Socket

Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated; Tightening torque: 0.5 Nm

