

# E10458



## Connection cable

VDOGH042MSS00,6A04STGH040MSS

Article no longer available - archive entry



### Electrical data

|                   |     |            |
|-------------------|-----|------------|
| Operating voltage | [V] | 10...30 DC |
|-------------------|-----|------------|

### Outputs

|                   |     |
|-------------------|-----|
| Electrical design | PNP |
|-------------------|-----|

### Operating conditions

|                     |      |          |
|---------------------|------|----------|
| Ambient temperature | [°C] | -25...90 |
|---------------------|------|----------|

|            |       |
|------------|-------|
| Protection | IP 67 |
|------------|-------|

### Mechanical data

|          |                |
|----------|----------------|
| Material | TPU (urethane) |
|----------|----------------|

|                      |                |
|----------------------|----------------|
| Molded-body material | TPU (urethane) |
|----------------------|----------------|

|              |                      |
|--------------|----------------------|
| Material nut | brass, nickel-plated |
|--------------|----------------------|

### Displays / operating elements


|         |                  |                 |
|---------|------------------|-----------------|
| Display | Switching status | 1 x LED, yellow |
|         | Power            | 1 x LED, green  |

### Remarks

|               |        |
|---------------|--------|
| Pack quantity | 1 pcs. |
|---------------|--------|

### Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated; Tightening torque: 0.5 Nm

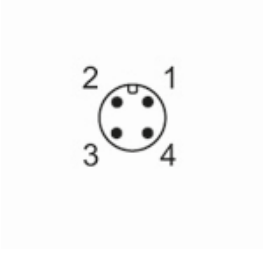

# E10458



## Connection cable

VDOGH042MSS00,6A04STGH040MSS

### Electrical connection

Cable: 0.6 m, PUR / PVC; 4 x 0.25 mm<sup>2</sup> (32 x Ø 0.1 mm )

### Connection



Core colors :  
BK = black  
BN = brown  
BU = blue  
WH = white

### Electrical connection - Socket

Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated; Tightening torque: 0.5 Nm

