


E10466



Connection cable

VDOGH040MSS0002A04STGH040MSS

Article no longer available - archive entry

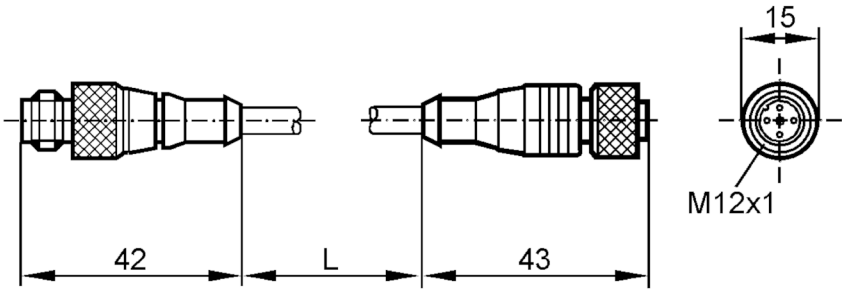

Electrical data		
Operating voltage	[V]	10...30 DC
Operating conditions		
Ambient temperature	[°C]	-25...85
Protection		IP 67
Mechanical data		
Dimensions	[mm]	15 x 15 x 42
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.
Electrical connection - plug		

Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated; Tightening torque: 0.5 Nm



E10466



Connection cable

VDOGH040MSS0002A04STGH040MSS

Electrical connection

Cable: 2 m, PUR / PVC; 4 x 0.25 mm²

Connection



Electrical connection - Socket

Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated; Tightening torque: 0.5 Nm

