

E10469




Female cordset

ADOGH040VAS0010A03

Article no longer available - archive entry

Alternative articles: EVC003
When selecting an alternative article and accessories please note that technical data may differ!

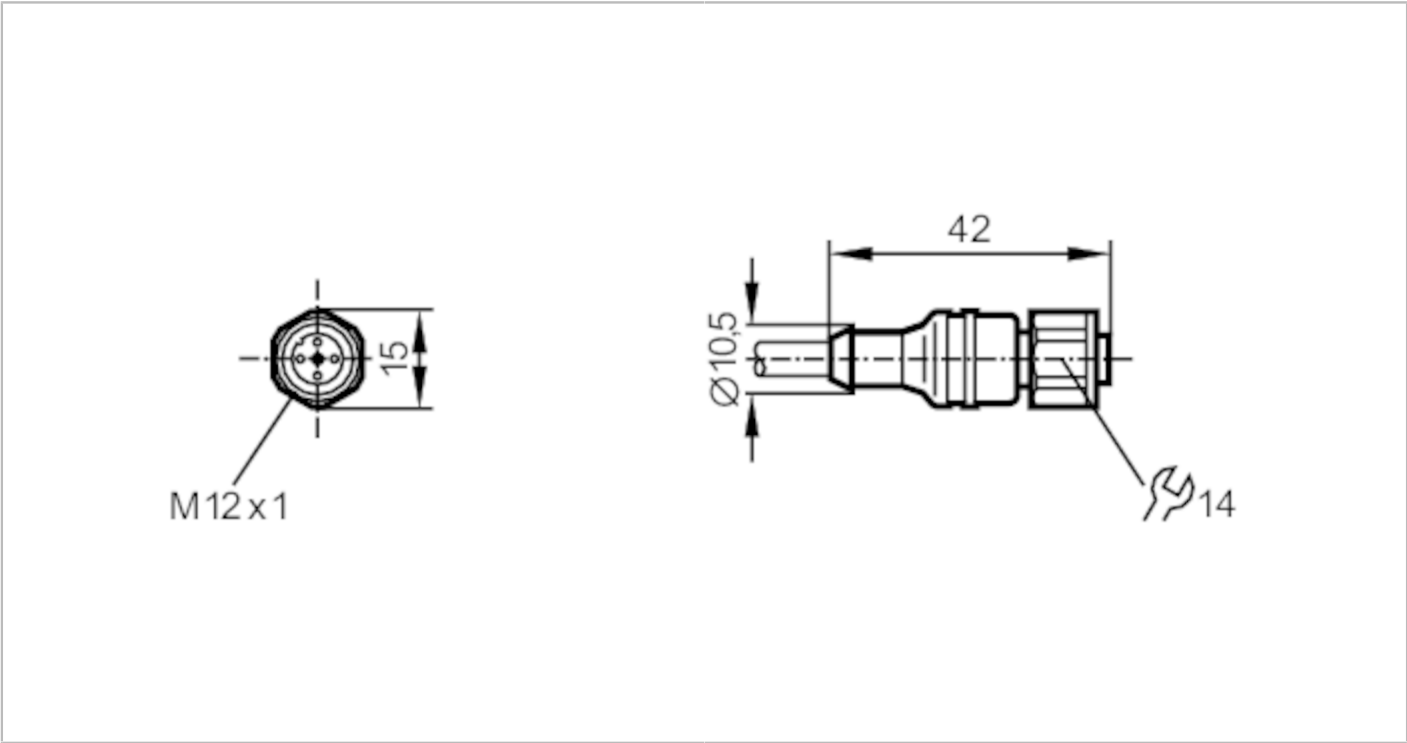

Electrical data		
Operating voltage	[V]	< 250 AC / < 300 DC
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Dimensions	[mm]	15 x 15 x 42
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Material nut		stainless steel (1.4404 / 316L)
Remarks		
Pack quantity		1 pcs.

E10469



Female cordset

ADOGH040VAS0010A03

Electrical connection

Cable: 10 m, PUR / PVC, orange, Ø 5 mm; 3 x 0.34 mm² (42 x Ø 0.1 mm)

Electrical connection - Socket

Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: stainless steel (1.4404 / 316L)



Connection



BK = Core colors :
BN = black
BU = brown
BK = blue