


E10471



Female cordset

ADOGH040MSS07,5F03

Article no longer available - archive entry

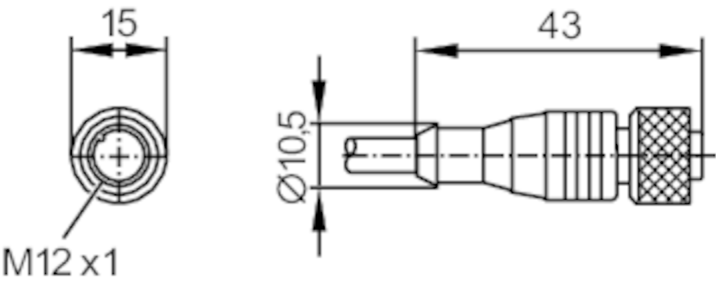

Electrical data		
Operating voltage	[V]	10...55 DC
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Dimensions	[mm]	15 x 15 x 43
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Material nut		brass, weld coated
Remarks		
Pack quantity		1 pcs.
Electrical connection		
Cable: 7.5 m, PVC, orange, Ø 5 mm; cross-linked; 3 x 0.34 mm² (19 x Ø 0.15 mm)		
Electrical connection - Socket		

Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, weld coated




E10471



Female cordset

ADOGH040MSS07,5F03

Connection

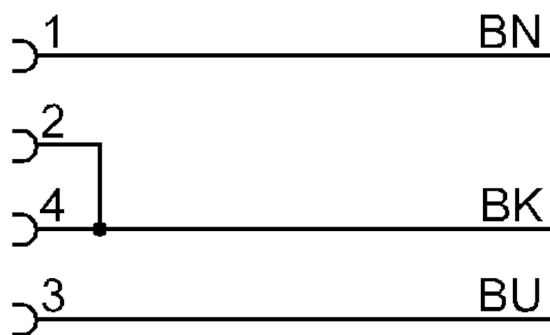

BN =
BK =
BU =

Core colors :
brown
black
blue