


E10474



Y/T splitter

ZDOAH040MSS0,07A02DOGH040MSS

Article no longer available - archive entry

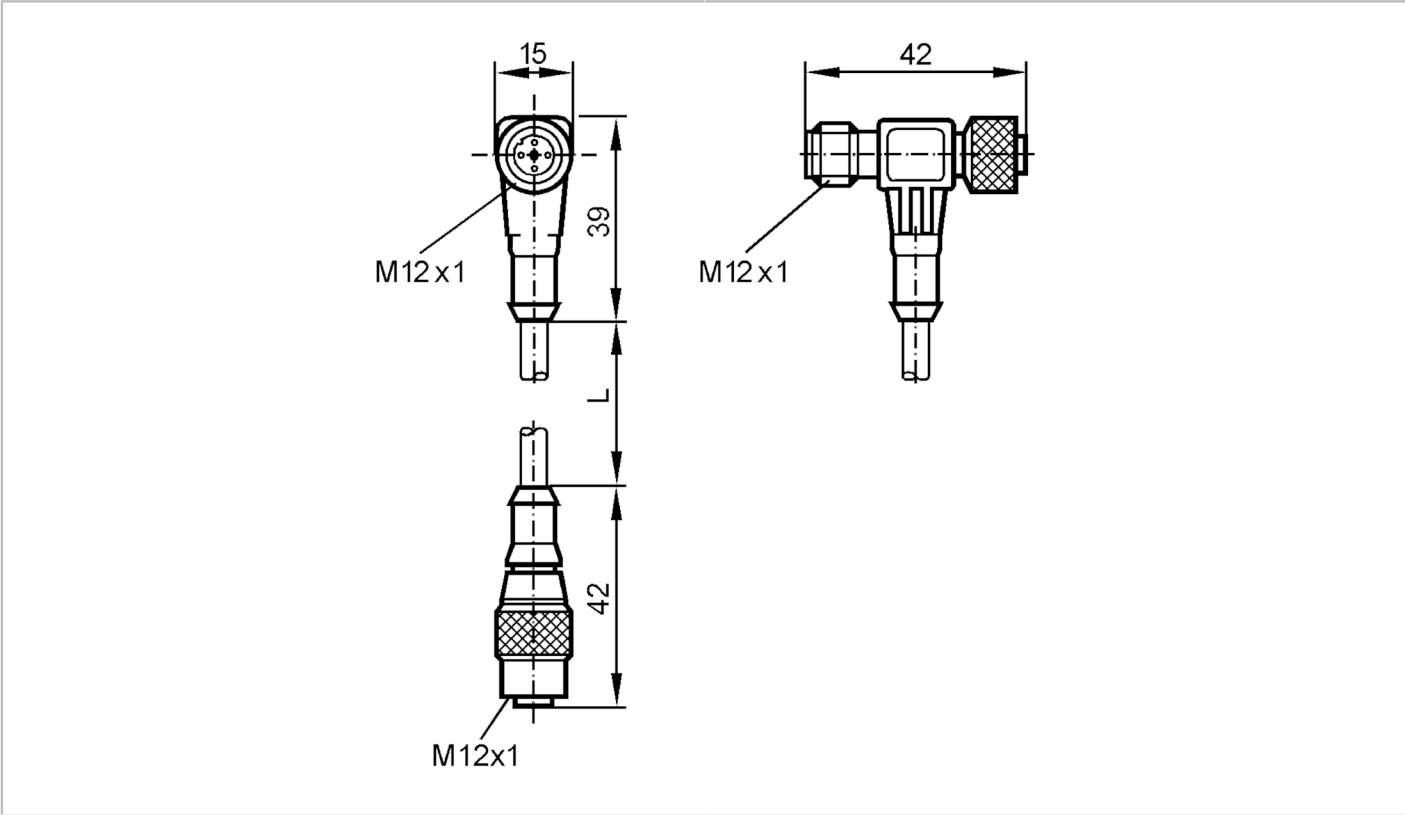

Electrical data		
Operating voltage	[V]	10...60 AC/DC
Max. current load per module/slot	[A]	4
Max. current load total	[A]	4
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Material nut		brass, nickel-plated
Number of ports splitter box		2
Remarks		
Pack quantity		1 pcs.

E10474



Y/T splitter

ZDOAH040MSS0,07A02DOGH040MSS

Electrical connection

Cable: 0.77 m, PUR / PVC, black, Ø 5 mm; 2 x 0.34 mm² (32 x Ø 0.1 mm)

Electrical connection - Socket

Connector: 2 x M12; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated; Tightening torque: 0.5 Nm



Electrical connection - plug

Connector: 2 x M12; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated; Tightening torque: 0.5 Nm



Connection

