

E10521




Female cordset

ADOGH040MSS0002F03

Article no longer available - archive entry

Alternative articles: E10915
When selecting an alternative article and accessories please note that technical data may differ!

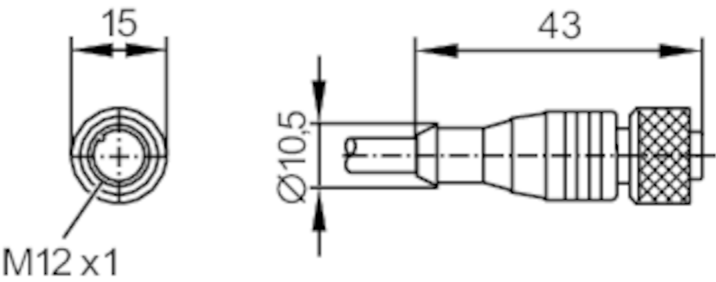

Electrical data		
Operating voltage	[V]	< 250 AC / < 300 DC
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Dimensions	[mm]	15 x 15 x 43
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Material nut		brass, weld coated
Remarks		
Pack quantity		1 pcs.

E10521



Female cordset

ADOGH040MSS0002F03

Electrical connection


Cable: 2 m, PVC, orange, Ø 5 mm; cross-linked; 3 x 0.34 mm² (19 x Ø 0.15 mm)

Electrical connection - Socket

Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, weld coated



Connection

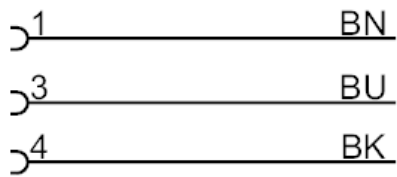

BN = Core colors :
BK = brown
BU = black
 blue