




Female cordset

ADOGH040MSS0005A03

Article no longer available - archive entry

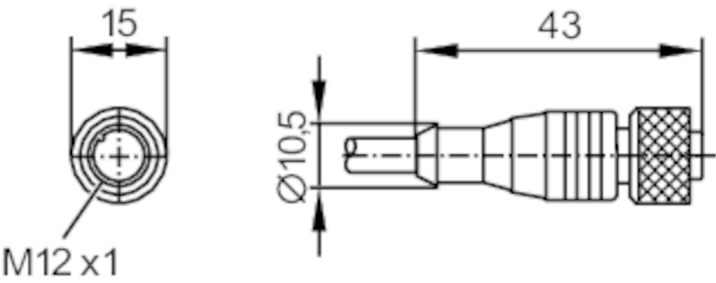

Electrical data		
Operating voltage	[V]	< 250 AC / < 300 DC
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Dimensions	[mm]	15 x 15 x 43
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.

Electrical connection	
Cable: 5 m, PUR / PVC, orange, Ø 5 mm; 3 x 0.34 mm²	

Electrical connection - Socket	
Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated	




E10522



Female cordset

ADOGH040MSS0005A03

Connection

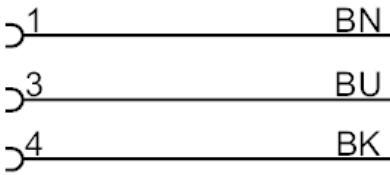

BN =	Core colors :	brown
BK =		black
BU =		blue