

E10542




Female cordset

ADOGF030PLS0005A03

Article no longer available - archive entry

Alternative articles: E11487
When selecting an alternative article and accessories please note that technical data may differ!

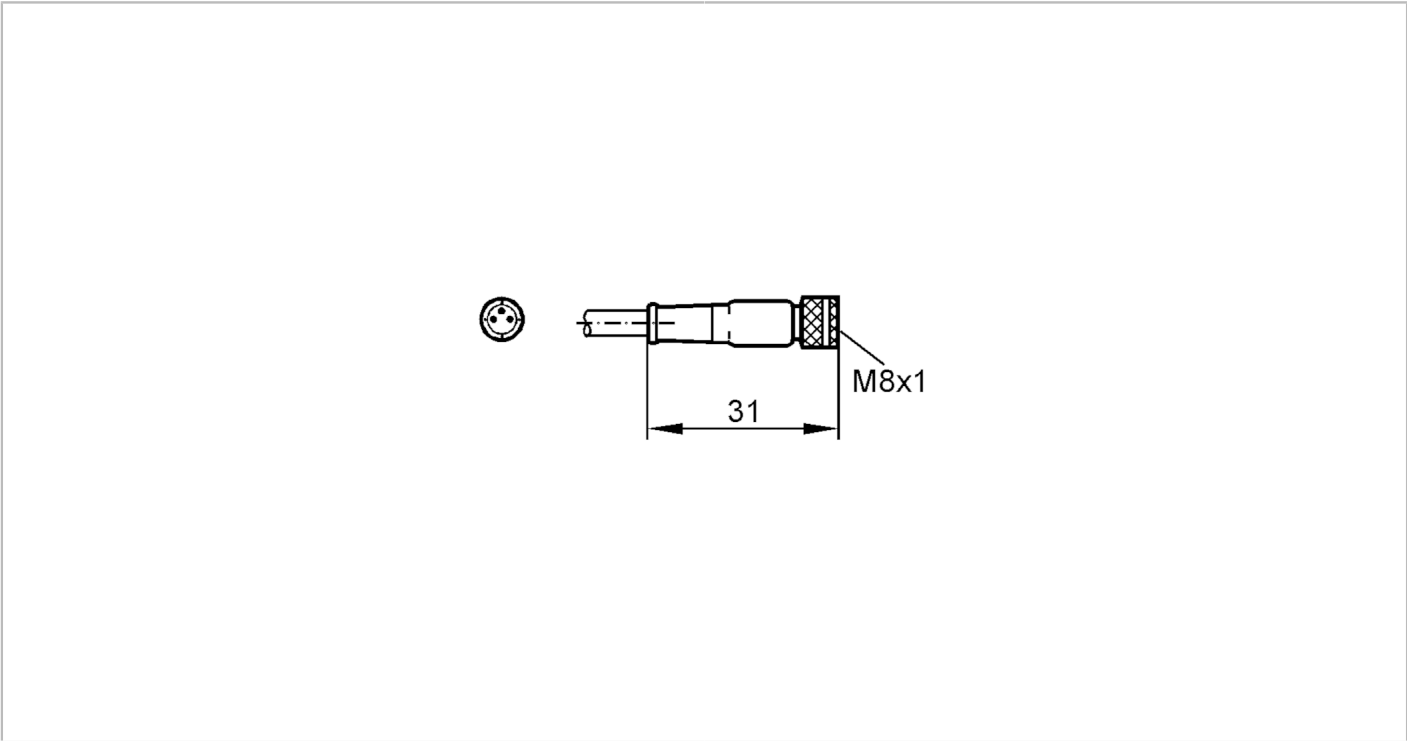

Electrical data		
Operating voltage	[V]	10...55 DC
Protection class		III
Operating conditions		
Ambient temperature	[°C]	-40...85
Protection		IP 67
Mechanical data		
Material		PUR
Molded-body material		PUR
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.

E10542



Female cordset

ADOGF030PLS0005A03

Electrical connection


Cable: 5 m, PUR / PVC, Ø 5 mm; 3 x 0.25 mm²

Electrical connection - Socket

Connector: 1 x M8, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated



Connection

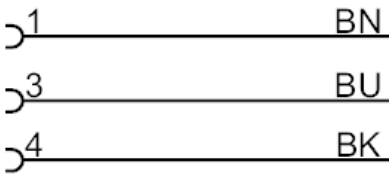

BN =	Core colors :
BK =	brown
BU =	black
	blue