

E10546



Female cordset

ADOAF032ZDS0002A03

Article no longer available - archive entry



Electrical data		
Operating voltage	[V]	10...30 DC
Protection class		III
Outputs		
Electrical design		PNP
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Dimensions	[mm]	17 x 10 x 26
Material		PUR
Molded-body material		PUR
Material nut		diecast zinc
Displays / operating elements		
Display	Switching status	1 x LED, yellow
	Power	1 x LED, green
Remarks		
Pack quantity		1 pcs.

E10546



Female cordset

ADOAF032ZDS0002A03

Electrical connection


Cable: 2 m, PUR / PVC, black, Ø 5 mm; 3 x 0.34 mm² (42 x Ø 0.1 mm)

Electrical connection - Socket

Connector: 1 x M8, angled; coding: A; Moulded body: PUR; Locking: diecast zinc



Connection

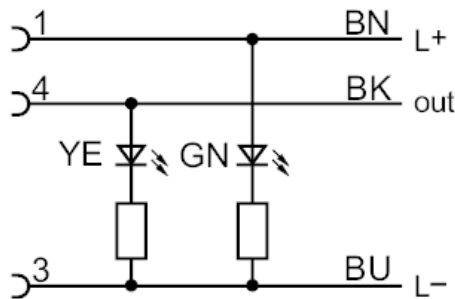

BN =	Core colors :
BK =	brown
BU =	black
	blue