


# E10550



## Connection cable

VDOGG030--S00,6A03STGH030MSS

Article no longer available - archive entry

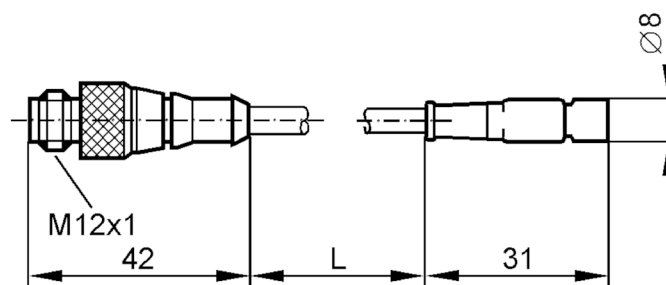

### Electrical data

Operating voltage	[V]	< 60 AC / < 75 DC
Protection class		III

### Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 67

### Mechanical data

Material	TPU (urethane)
Material nut	brass, nickel-plated / brass, nickel-plated

### Remarks

Pack quantity	1 pcs.
---------------	--------

### Electrical connection - plug

Connector: 1 x M12, straight; Moulded body: TPU (urethane); Locking: brass, nickel-plated



# E10550




## Connection cable

VDOGG030--S00,6A03STGH030MSS

### Electrical connection


Cable: 0.6 m, PUR / PVC, orange,  $\varnothing$  5 mm; 3 x 0.34 mm<sup>2</sup> (42 x  $\varnothing$  0.1 mm )

### Connection

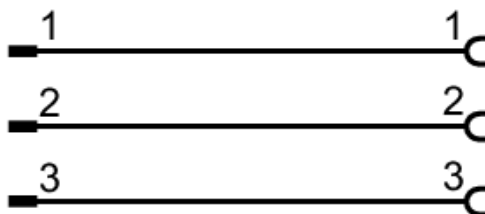

### Electrical connection - Socket

 Connector: 1 x M8, straight; Moulded body: TPU (urethane); Locking: brass, nickel-plated



Article no longer available - archive entry