


E10551



Connection cable

VDOAG032--S00,3A03STGH030MSS

Article no longer available - archive entry

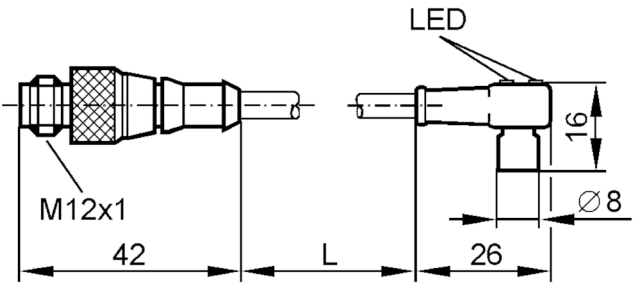

Electrical data		
Operating voltage	[V]	10...30 DC
Protection class		III
Outputs		
Electrical design		PNP
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Material		PUR
Molded-body material		PUR
Material nut		brass, nickel-plated
Displays / operating elements		
Display	Switching status	1 x LED, yellow
	Power	1 x LED, green
Remarks		
Pack quantity		1 pcs.

E10551



Connection cable

VDOAG032--S00,3A03STGH030MSS

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated



Electrical connection

Cable: 0.3 m, PUR / PVC, orange, Ø 5 mm; 3 x 0.34 mm² (42 x Ø 0.1 mm)

Connection



Electrical connection - Buchse



Connection



E10551



Connection cable

VDOAG032--S00,3A03STGH030MSS

Electrical connection - Socket

Connector: 1 x M8, angled; Moulded body: PUR; Locking: brass, nickel-plated