


# E10553



## Connection cable

VDOAG032--S0002A03STGH030MSS

Article no longer available - archive entry

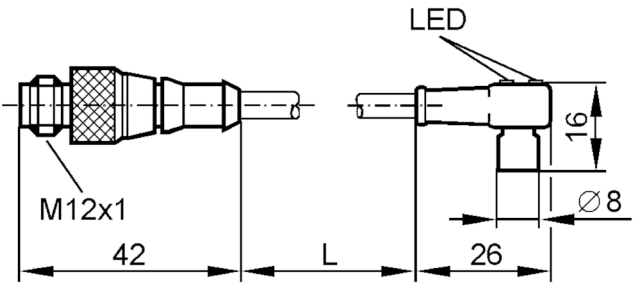

| Electrical data               |                  |                      |
|-------------------------------|------------------|----------------------|
| Operating voltage             | [V]              | 10...30 DC           |
| Protection class              |                  | III                  |
| Outputs                       |                  |                      |
| Electrical design             |                  | PNP                  |
| Operating conditions          |                  |                      |
| Ambient temperature           | [°C]             | -25...90             |
| Protection                    |                  | IP 67                |
| Mechanical data               |                  |                      |
| Material                      |                  | PUR                  |
| Molded-body material          |                  | PUR                  |
| Material nut                  |                  | brass, nickel-plated |
| Displays / operating elements |                  |                      |
| Display                       | Switching status | 1 x LED, yellow      |
|                               | Power            | 1 x LED, green       |
| Remarks                       |                  |                      |
| Pack quantity                 |                  | 1 pcs.               |

# E10553



## Connection cable

VDOAG032--S0002A03STGH030MSS

### Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated



 
### Electrical connection

Cable: 2 m, PUR / PVC, orange, Ø 5 mm; 3 x 0.34 mm<sup>2</sup> (42 x Ø 0.1 mm )

#### Connection



### Electrical connection - Buchse



#### Connection



# E10553



## Connection cable

VDOAG032--S0002A03STGH030MSS

### Electrical connection - Socket

Connector: 1 x M8, angled; Moulded body: PUR; Locking: brass, nickel-plated