


E10566



Female cordset

ADOAH042MSS0010E03

Article no longer available - archive entry

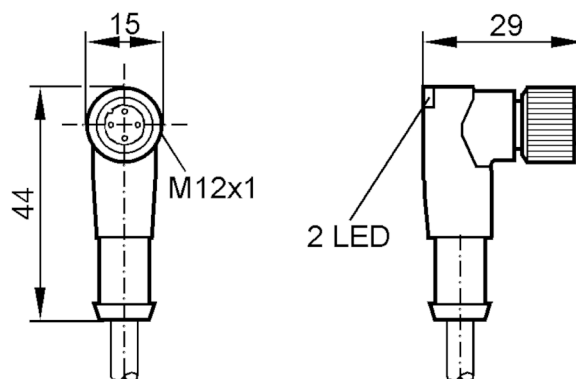

Electrical data

Operating voltage [V] 10...30 DC

Outputs

Electrical design PNP

Operating conditions

Ambient temperature [°C] -20...70

Protection IP 67

Mechanical data

Dimensions [mm] 29 x 15 x 44

Material PA 6.6

Molded-body material PA 6.6

Material nut aluminum

Displays / operating elements

Display	Switching status	1 x LED, yellow
	Power	1 x LED, green

Remarks

Pack quantity 1 pcs.

E10566



Female cordset

ADOAH042MSS0010E03

Electrical connection


Cable: 10 m, PUR, orange, Ø 4.5 mm; 3 x 0.34 mm²

Electrical connection - Socket

Connector: 1 x M12, angled; coding: A; Moulded body: PA 6.6; Locking: aluminum



Connection

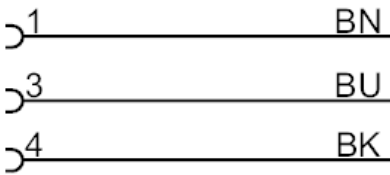

BN =	Core colors :
BK =	brown
BU =	black
	blue