


E10568



Connection cable

VDOAH042MSS0002B03STGH040MSS

Article no longer available - archive entry

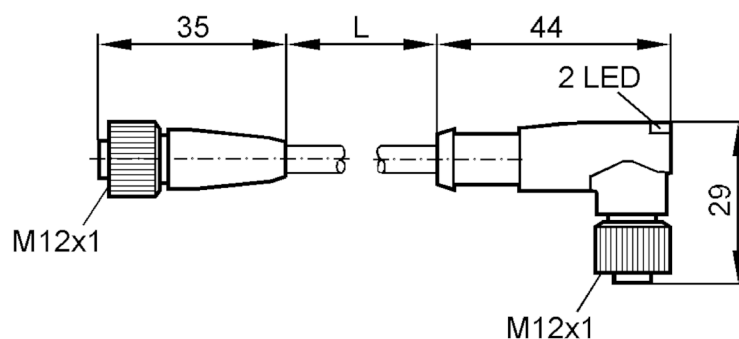

Electrical data

Operating voltage [V] 10...30 DC

Outputs

Electrical design PNP

Operating conditions

Ambient temperature [°C] -20...70

Protection IP 67

Mechanical data

Material PA 6.6

Molded-body material PA 6.6

Material nut aluminum, black anodized

Displays / operating elements

Display	Switching status	1 x LED, yellow
	Power	1 x LED, green

Remarks

Pack quantity 1 pcs.

E10568



Connection cable

VDOAH042MSS0002B03STGH040MSS

Electrical connection - plug


Connector: 1 x M12, straight; coding: A; Moulded body: PA 6.6; Locking: aluminum, black anodized



Electrical connection

Cable: 2 m, PUR, orange; cross-linked; 3 x 0.34 mm²

Connection

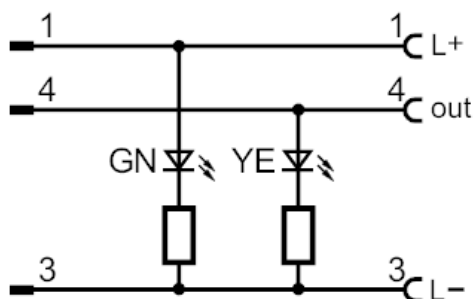

Electrical connection - Socket

Connector: 1 x M12, angled; coding: A; Moulded body: PA 6.6; Locking: aluminum, black anodized

