

E10589




Female cordset

ADOAH050MSS0005A05

Article no longer available - archive entry

Alternative articles: EVC074
When selecting an alternative article and accessories please note that technical data may differ!

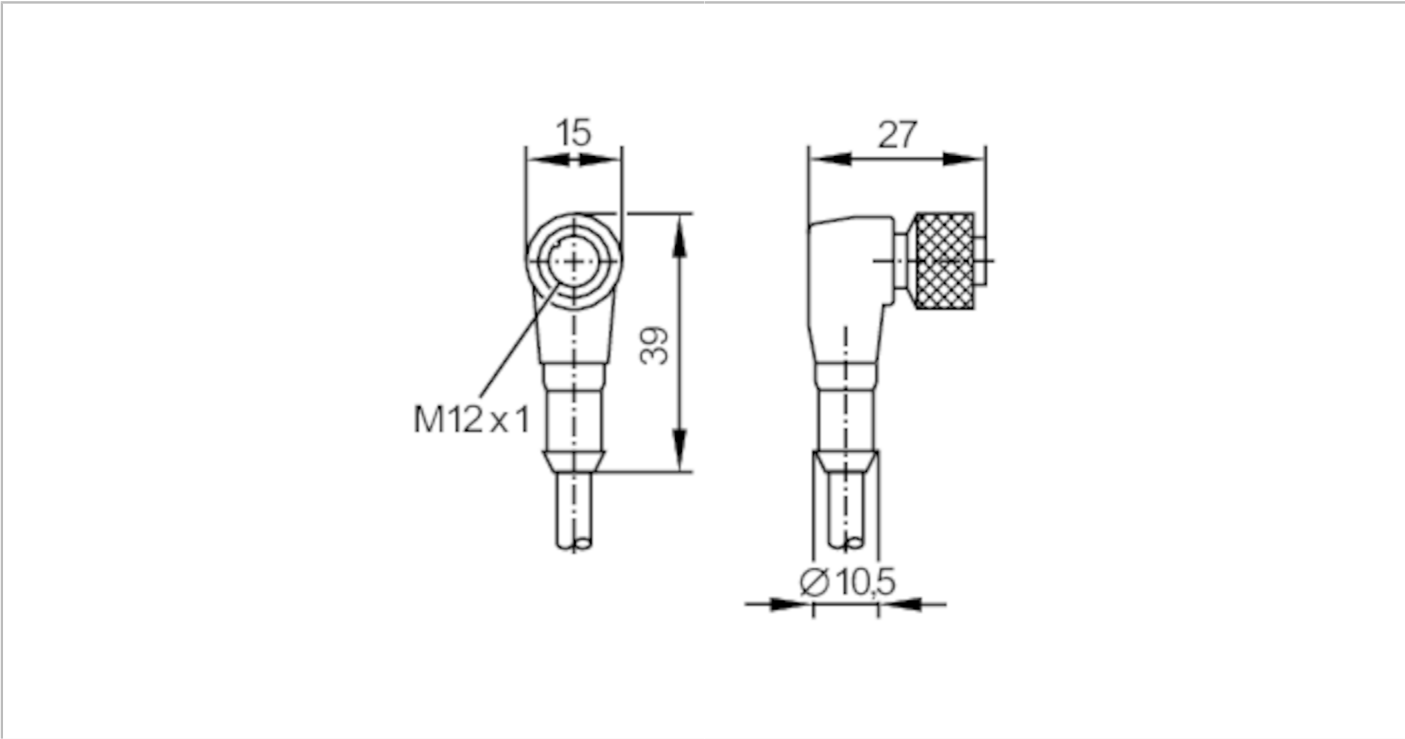

Electrical data		
Operating voltage	[V]	< 30 AC / < 36 DC
Outputs		
Electrical design		PNP
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Dimensions	[mm]	27 x 15 x 39
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.

E10589



Female cordset

ADOAH050MSS0005A05

Electrical connection

Cable: 5 m, PUR / PVC, orange, Ø 5.2 mm; 5 x 0.34 mm² (42 x Ø 0.1 mm)

Electrical connection - Socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated



Connection

1	BN
2	WH
3	BU
4	BK
5	GY

BN =	Core colors :
BK =	brown
BU =	black
WH =	blue
	white