


E10590



Female cordset

ADOAH042VAS0005E03

Article no longer available - archive entry

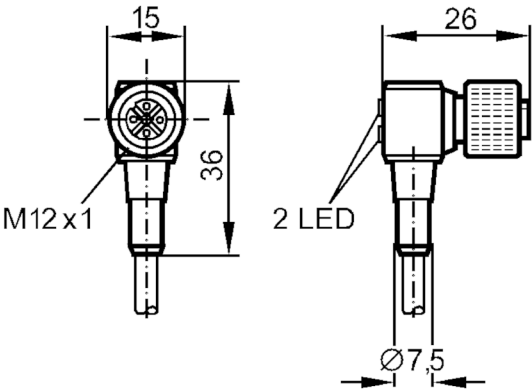

Electrical data

Operating voltage	[V]	10...30 DC
-------------------	-----	------------

Outputs

Electrical design	PNP
-------------------	-----

Operating conditions

Ambient temperature	[°C]	-25...90
---------------------	------	----------

Protection	IP 67
------------	-------

Mechanical data

Material	PUR
----------	-----

Molded-body material	PUR
----------------------	-----

Material nut	stainless steel (1.4305 / 303)
--------------	--------------------------------

Remarks


Pack quantity	1 pcs.
---------------	--------

Electrical connection

Cable: 5 m, PVC, black, Ø 4.5 mm; 3 x 0.34 mm² (182 x Ø 0.05 mm)

Electrical connection - Socket

 Connector: 1 x M12, angled; coding: A; Moulded body: PUR; Locking: stainless steel (1.4305 / 303)




E10590



Female cordset

ADOAH042VAS0005E03

Connection

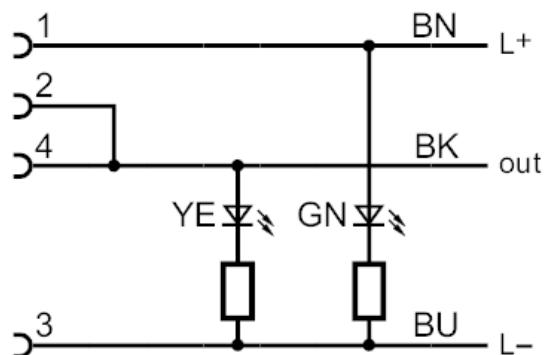

BK = Core colors :
BN = black
BU = brown
blue