


E10593



Female cordset

ADOAH042VAS0025E03

Article no longer available - archive entry

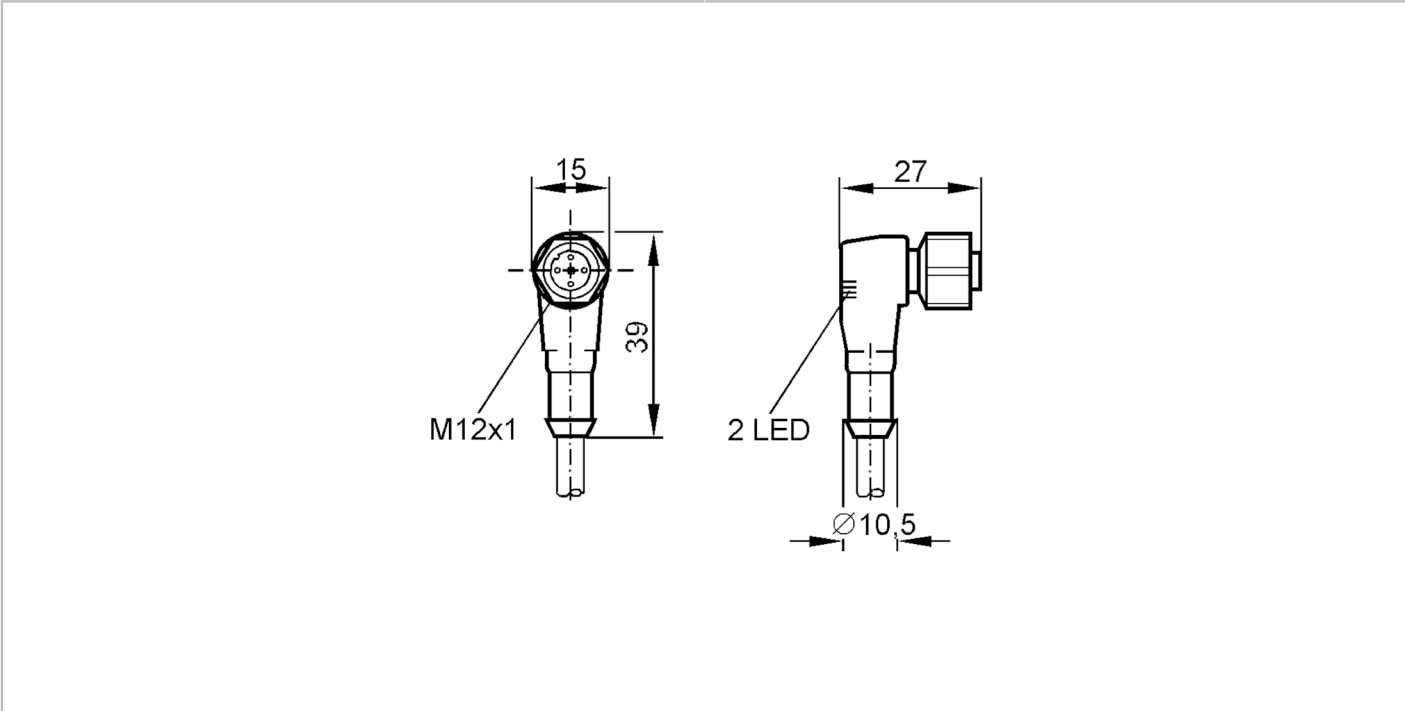

Electrical data		
Operating voltage	[V]	10...30 DC
Outputs		
Electrical design		PNP
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Material		TPU (urethane) transparent
Molded-body material		TPU (urethane), transparent
Material nut		stainless steel (1.4404 / 316L)
Remarks		
Pack quantity		1 pcs.

E10593



Female cordset

ADOAH042VAS0025E03

Electrical connection

Cable: 25 m, PVC, orange, Ø 5 mm; 3 x 0.34 mm²

Electrical connection - Socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU (urethane), transparent; Locking: stainless steel (1.4404 / 316L);
Tightening torque: 0.5 Nm



Connection



Core colors :
BK = black
BN = brown
BU = blue