

E10600




Connection cable

VDOAF030MSS00,6A03STGF030MSS

Article no longer available - archive entry

Alternative articles: E11325
When selecting an alternative article and accessories please note that technical data may differ!

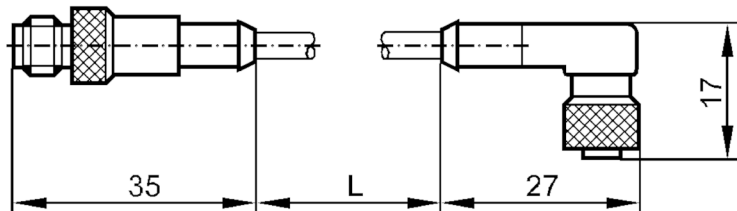

Electrical data

Operating voltage	[V]	< 60 AC/DC
Protection class		III

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 68

Mechanical data

Material	PUR
Molded-body material	PUR
Material nut	diecast zinc, nickel-plated

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection - plug

Connector: 1 x M8, straight; coding: A; Moulded body: PUR; Locking: diecast zinc, nickel-plated



E10600



Connection cable

VDOAF030MSS00,6A03STGF030MSS

Electrical connection

Cable: 0.6 m, PUR / PVC; 3 x 0.25 mm² (128 x Ø 0.05 mm)

Connection



Electrical connection - Socket

Connector: 1 x M8, angled; coding: A; Moulded body: PUR; Locking: diecast zinc, nickel-plated

