


E10601



Connection cable

VDOAF030MSS00,8A03STGF030MSS

Article no longer available - archive entry

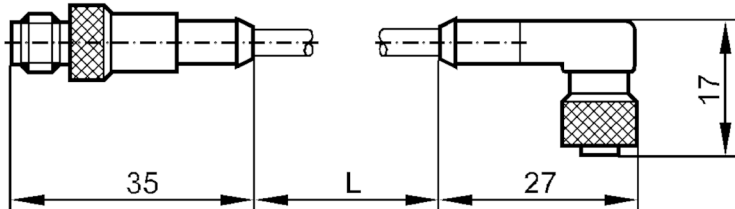

Electrical data		
Operating voltage	[V]	< 60 AC/DC
Protection class		III


Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 68

Mechanical data		
Material		PUR
Molded-body material		PUR
Material nut		diecast zinc, nickel-plated

Remarks		
Pack quantity		1 pcs.

Electrical connection - plug

 Connector: 1 x M8, straight; coding: A; Moulded body: PUR; Locking: diecast zinc, nickel-plated



E10601




Connection cable

VDOAF030MSS00,8A03STGF030MSS

Electrical connection

Cable: 0.8 m, PUR / PVC; 3 x 0.25 mm² (128 x Ø 0.05 mm)

Connection

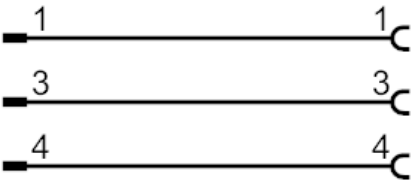

Electrical connection - Socket

Connector: 1 x M8, angled; coding: A; Moulded body: PUR; Locking: diecast zinc, nickel-plated

