


# E10607



## Connection cable


VDOGF030MSS01,5A03STGF030MSS

Article no longer available - archive entry

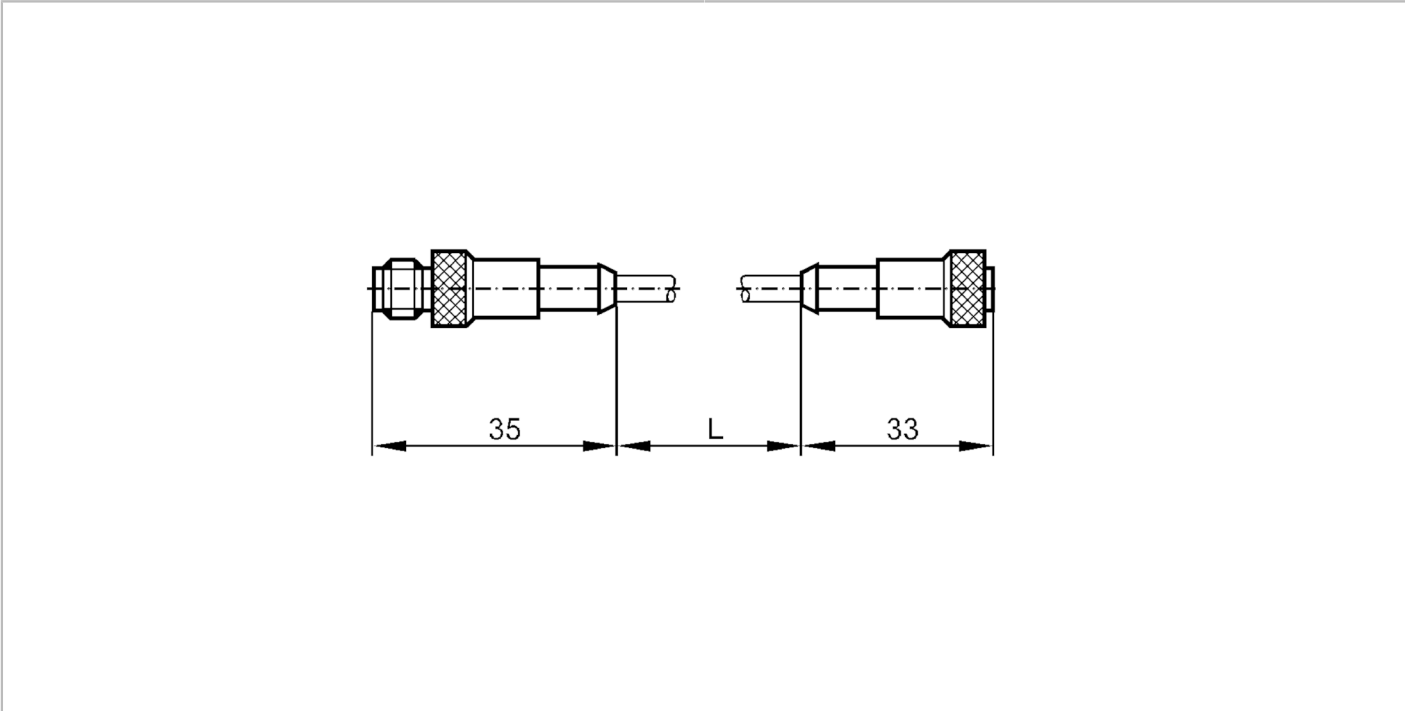

| Electrical data              |      |                             |
|------------------------------|------|-----------------------------|
| Operating voltage            | [V]  | < 60 AC/DC                  |
| Protection class             |      | III                         |
| Operating conditions         |      |                             |
| Ambient temperature          | [°C] | -25...90                    |
| Protection                   |      | IP 68                       |
| Mechanical data              |      |                             |
| Material                     |      | PUR                         |
| Molded-body material         |      | PUR                         |
| Material nut                 |      | diecast zinc, nickel-plated |
| Remarks                      |      |                             |
| Pack quantity                |      | 1 pcs.                      |
| Electrical connection - plug |      |                             |

Connector: 1 x M8, straight; coding: A; Moulded body: PUR; Locking: diecast zinc, nickel-plated

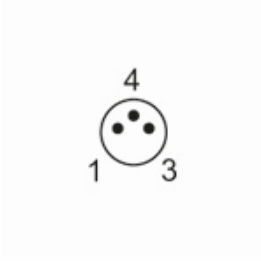

# E10607



## Connection cable

VDOGF030MSS01,5A03STGF030MSS

### Electrical connection

Cable: 1.5 m, PUR / PVC; 3 x 0.25 mm<sup>2</sup> (128 x Ø 0.05 mm )

### Connection



### Electrical connection - Socket

Connector: 1 x M8, straight; coding: A; Moulded body: PUR; Locking: diecast zinc, nickel-plated

