


E10617



Connection cable

VDOAF032ZDS00,6A03STGH030ZDS

Article no longer available - archive entry

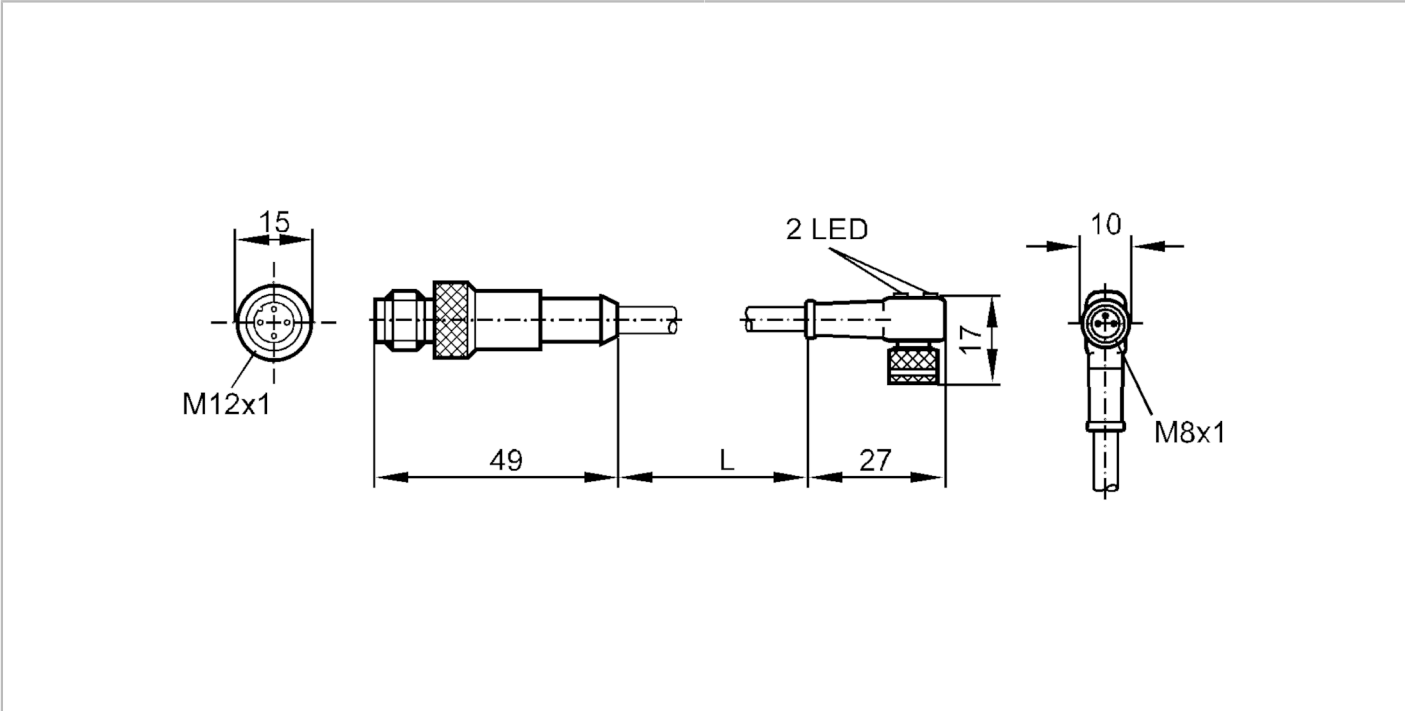

Electrical data		
Operating voltage	[V]	10...30 DC
Protection class		III
Outputs		
Electrical design		PNP
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 68
Mechanical data		
Dimensions	[mm]	15 x 15 x 46
Material		PUR
Molded-body material		PUR
Material nut		diecast zinc, nickel-plated
Displays / operating elements		
Display	Switching status	1 x LED, yellow
	Power	1 x LED, green
Remarks		
Pack quantity		1 pcs.

E10617



Connection cable

VDOAF032ZDS00,6A03STGH030ZDS

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: diecast zinc, nickel-plated



Electrical connection

Cable: 0.6 m, PUR / PVC; 3 x 0.34 mm² (182 x Ø 0.05 mm)

Connection



Electrical connection - Buchse



Connection



E10617



Connection cable

VDOAF032ZDS00,6A03STGH030ZDS

Electrical connection - Socket

Connector: 1 x M8, angled; Moulded body: PUR; Locking: diecast zinc, nickel-plated