


E10619



Female wirable connectors

SDOAF030ZDSFKPK


Article no longer available - archive entry

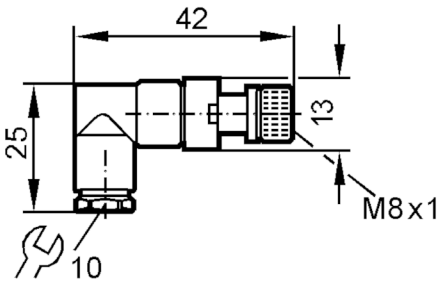

Electrical data		
Operating voltage	[V]	< 60 AC/DC
Protection class		III
Operating conditions		
Ambient temperature	[°C]	-25...70
Protection		IP 67
Mechanical data		
Dimensions	[mm]	25 x 13 x 42
Material		PA
Molded-body material		PA
Material nut		ZnAl / Ni
Remarks		
Pack quantity		1 pcs.

Electrical connection - Socket

 Connector: 1 x M8, angled; coding: A; Moulded body: PA; Locking: ZnAl / Ni



E10619



Female wirable connectors

SDOAF030ZDSFKPK

Connection

