

# E10620




## Female wirable connectors

SDOGF030ZDSFKPK

Article no longer available - archive entry

Alternative articles: E11552  
When selecting an alternative article and accessories please note that technical data may differ!

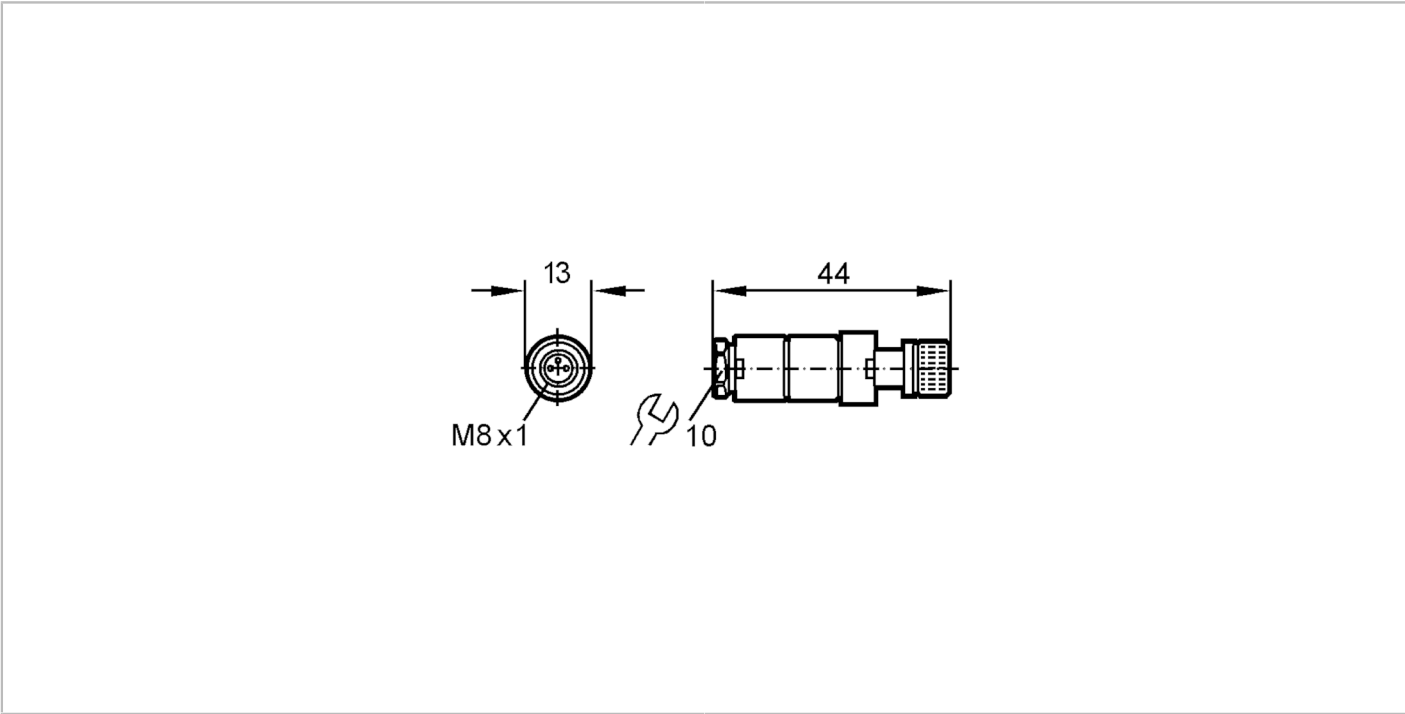

### Electrical data

|                   |     |            |
|-------------------|-----|------------|
| Operating voltage | [V] | < 60 AC/DC |
| Protection class  |     | III        |

### Operating conditions

|                     |      |          |
|---------------------|------|----------|
| Ambient temperature | [°C] | -25...70 |
| Protection          |      | IP 67    |

### Mechanical data


|                      |      |              |
|----------------------|------|--------------|
| Dimensions           | [mm] | 13 x 13 x 44 |
| Material             |      | PA           |
| Molded-body material |      | PA           |
| Material nut         |      | ZnAl / Ni    |

### Remarks

|               |  |        |
|---------------|--|--------|
| Pack quantity |  | 1 pcs. |
|---------------|--|--------|

### Electrical connection - Socket

Connector: 1 x M8, straight; coding: A; Moulded body: PA; Locking: ZnAl / Ni

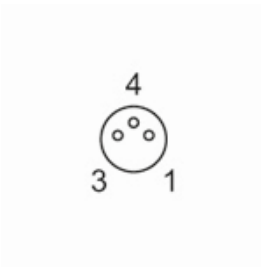

# E10620



## Female wirable connectors

SDOGF030ZDSFKPK

### Connection

