



Female cordset

ADOGG030--S0010A03

Article no longer available - archive entry

No scale drawing available

Application

System	Halogen-free
--------	--------------

Electrical data

Operating voltage [V]	< 60 AC / < 75 DC
Protection class	III

Operating conditions

Ambient temperature [°C]	-25...90
Protection	IP 65

Mechanical data

Dimensions [mm]	8 x 8 x 31
Material	TPU (urethane)
Molded-body material	TPU (urethane)

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection

Cable: 10 m, PUR / PVC, Halogen-free, orange, Ø 5 mm; 3 x 0.34 mm² (42 x Ø 0.1 mm)

Electrical connection - Socket

Connector: 1 x M8, straight; coding: A; Moulded body: TPU (urethane)




E10623



Female cordset

ADOGG030--S0010A03

Connection

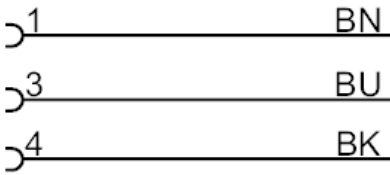

	Core colors :
BK =	black
BN =	brown
BU =	blue