

E10627



Female cordset


ADOGH050MSS0005E05

Article no longer available - archive entry



Electrical data		
Operating voltage	[V]	< 30 AC / < 36 DC
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Dimensions	[mm]	15 x 15 x 43
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.
Electrical connection		
Cable: 5 m, PVC, orange, Ø 5.7 mm; 5 x 0.34 mm² (42 x Ø 0.1 mm)		
Electrical connection - Socket		

Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated

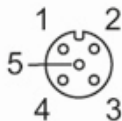


E10627



Female cordset

ADOGH050MSS0005E05

Connection

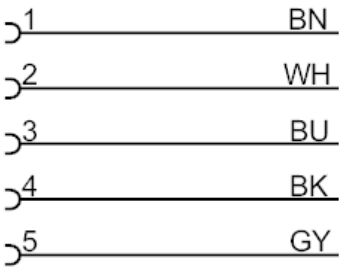

	Core colors :
BK =	black
BN =	brown
BU =	blue
GY =	grey
WH =	white