


E10646



Female cordset

ADOGH040VAS0020A03

Article no longer available - archive entry

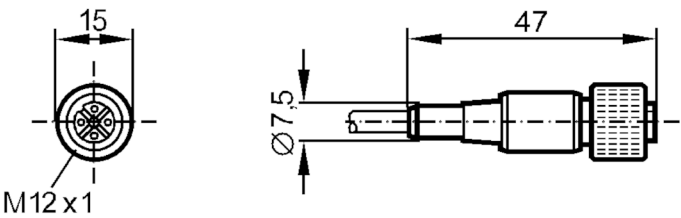

Electrical data		
Operating voltage	[V]	< 250 AC/DC
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Dimensions	[mm]	15 x 15 x 47
Material		PUR
Molded-body material		PUR
Material nut		stainless steel (1.4305 / 303)
Remarks		
Pack quantity		1 pcs.
Electrical connection		
Cable: 20 m, PUR / PVC, black, Ø 4.5 mm; 3 x 0.34 mm² (182 x Ø 0.05 mm)		
Electrical connection - Socket		
Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: stainless steel (1.4305 / 303)		




E10646



Female cordset

ADOGH040VAS0020A03

Connection

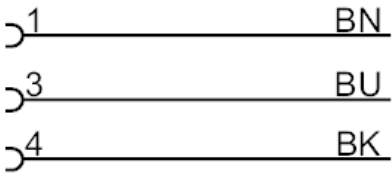

	Core colors :
BK =	black
BN =	brown
BU =	blue