


E10658



Connection cable

VDOAF032MSS01,5A03STGH030MSS

Article no longer available - archive entry

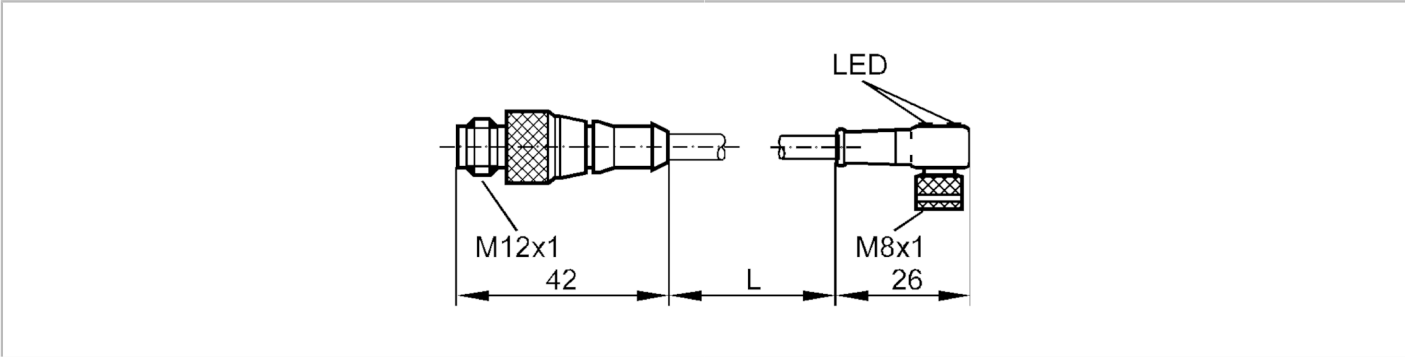

Electrical data

Operating voltage	[V]	10...30 DC
Protection class		III

Outputs

Electrical design	PNP
-------------------	-----

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 67

Mechanical data

Material	PUR
Molded-body material	PUR
Material nut	brass, nickel-plated

Displays / operating elements


Display	Switching status	1 x LED, yellow
	Power	1 x LED, green

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated

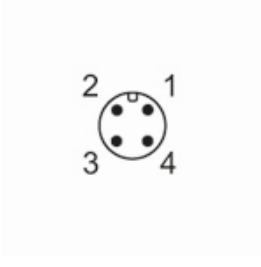

E10658




Connection cable

VDOAF032MSS01,5A03STGH030MSS

Electrical connection

Cable: 1.5 m, PUR / PVC; 3 x 0.34 mm² (42 x Ø 0.1 mm)


Connection

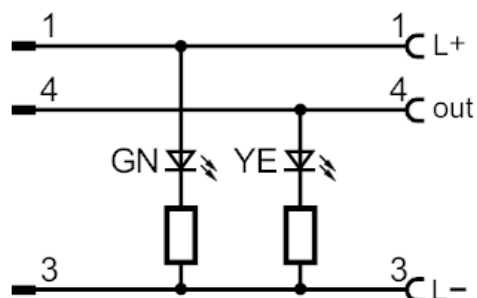

Electrical connection - Buchse



Connection

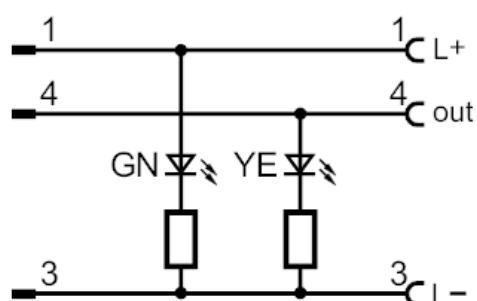

Electrical connection - Socket

Connector: 1 x M8, angled; Moulded body: PUR; Locking: brass, nickel-plated