


E10666



Connection cable

VDOAH042MSS00,3A03STGH030MSS

Article no longer available - archive entry

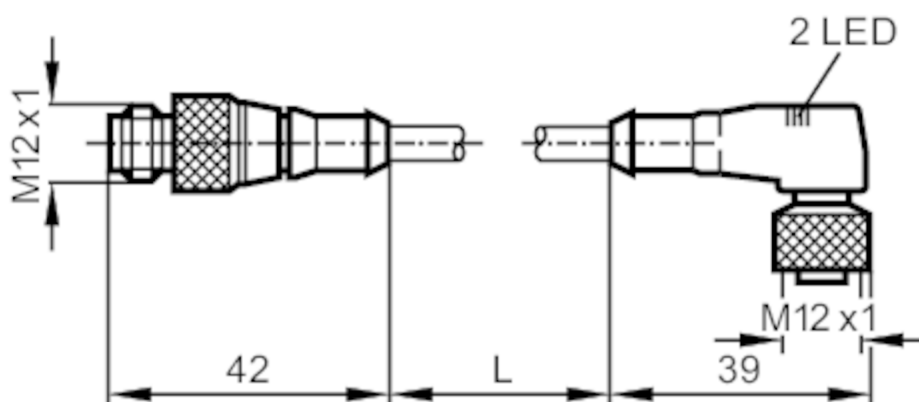

Electrical data

Operating voltage [V] 10...30 DC

Outputs

Electrical design PNP

Operating conditions

Ambient temperature [°C] -25...90

Protection IP 67

Mechanical data

Material PUR

Molded-body material PUR

Material nut brass, nickel-plated

Displays / operating elements

Display	Switching status	
	Power	1 x LED, yellow 1 x LED, green

Remarks

Pack quantity 1 pcs.

E10666



Connection cable

VDOAH042MSS00,3A03STGH030MSS

Electrical connection - plug


Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Tightening torque: 0.5 Nm



Electrical connection

Cable: 0.3 m, PUR / PVC, orange, Ø 5 mm; 3 x 0.34 mm² (42 x Ø 0.1 mm)

Connection

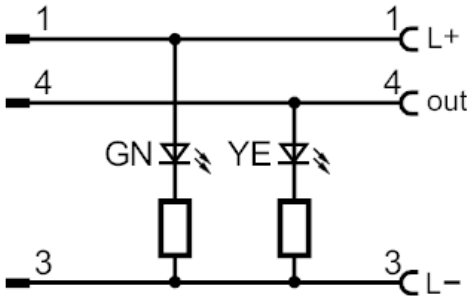

Core colors :
BK = black
BN = brown
BU = blue

Electrical connection - Socket

Connector: 1 x M12, angled; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Tightening torque: 0.5 Nm

