


E10667



Patchcords with valve plug

VVSAC041MSS0003B03STGH030MSS

Article no longer available - archive entry

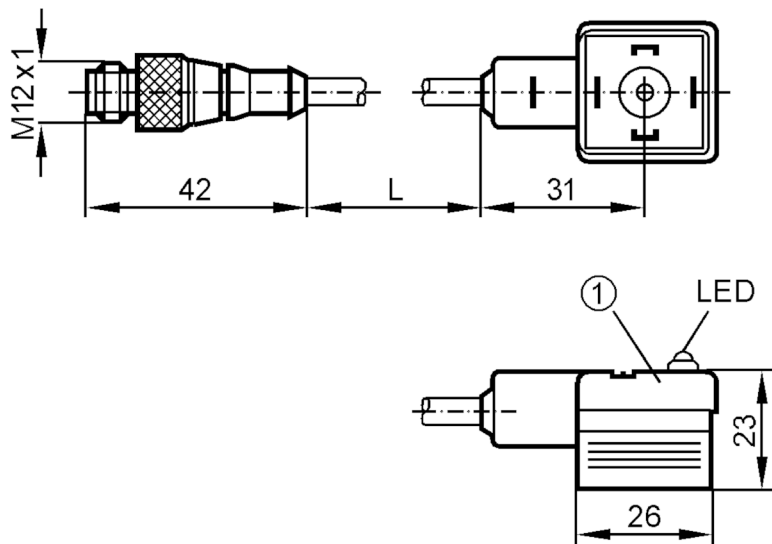

1 grey

Electrical data		
Operating voltage	[V]	< 24 AC/DC
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 65
Mechanical data		
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Material nut		brass, nickel-plated
Displays / operating elements		
Display	Switching status	1 x LED, yellow
Remarks		
Pack quantity		1 pcs.
Electrical connection - plug		
Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated		



E10667




Patchcords with valve plug

VVSAC041MSS0003B03STGH030MSS

Electrical connection

Cable: 3 m, PUR; 3 x 0.34 mm²

Connection

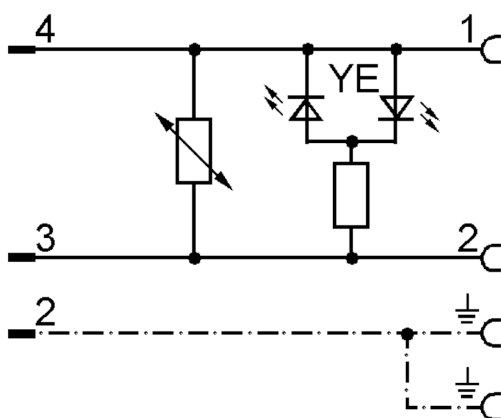

Electrical connection - Socket

Connector: 1 x valve type A DIN, angled; Moulded body: TPU (urethane); Locking: brass, nickel-plated

