


E10669



Patchcords with valve plug

VVSAC040MSS0001B03STGH040MSS

Article no longer available - archive entry

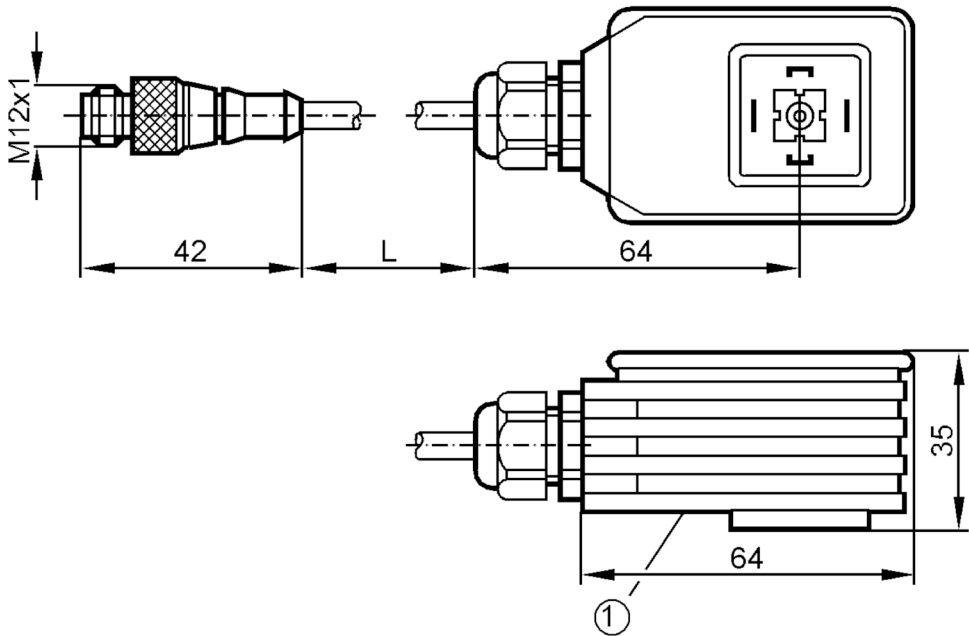

1 black

Application	
Design	with amplifier
Electrical data	
Operating voltage	[V] 12...40 DC
Operating conditions	
Ambient temperature	[°C] -25...90
Protection	IP 65
Mechanical data	
Material	TPU (urethane)
Molded-body material	TPU (urethane)
Material nut	brass, nickel-plated
Remarks	
Pack quantity	1 pcs.
Electrical connection - plug	

Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated



E10669




Patchcords with valve plug

VVSAC040MSS0001B03STGH040MSS

Electrical connection

Cable: 1 m, PUR; 3 x 0.5 mm²

Connection

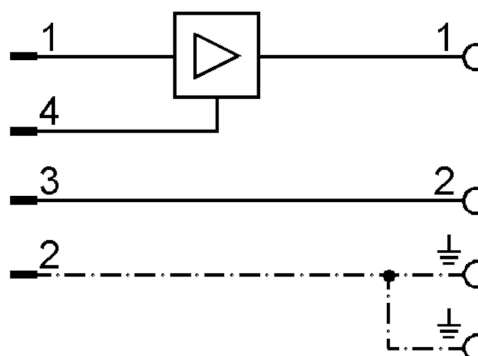

Electrical connection - Socket

Connector: 1 x valve type A DIN, angled; Moulded body: TPU (urethane); Locking: brass, nickel-plated

