

E10683




Connection cable

VDOAH040MSS0001B04STGH040MSS

Article no longer available - archive entry

Alternative articles: EVC017
When selecting an alternative article and accessories please note that technical data may differ!

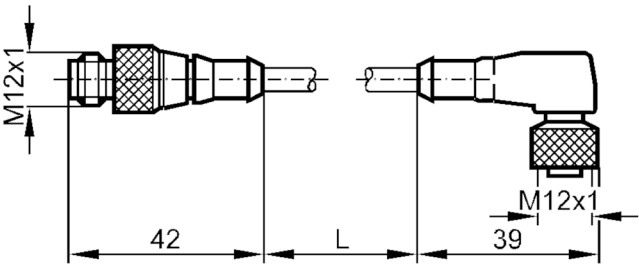

Electrical data		
Operating voltage	[V]	10...30 DC
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Material		PUR
Molded-body material		PUR
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.
Electrical connection - plug		

Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated



E10683




Connection cable

VDOAH040MSS0001B04STGH040MSS

Electrical connection

Cable: 1 m, PUR, orange, Ø 5 mm; 4 x 0.25 mm² (128 x Ø 0.05 mm)

Connection

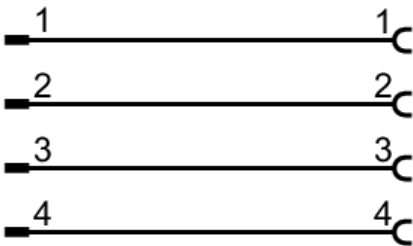

Electrical connection - Socket

Connector: 1 x M12, angled; coding: A; Moulded body: PUR; Locking: brass, nickel-plated

