

E10692




Connection cable

VDOGH040MSS00,6B04STGH040MSS

Article no longer available - archive entry


Alternative articles: EVC011
When selecting an alternative article and accessories please note that technical data may differ!

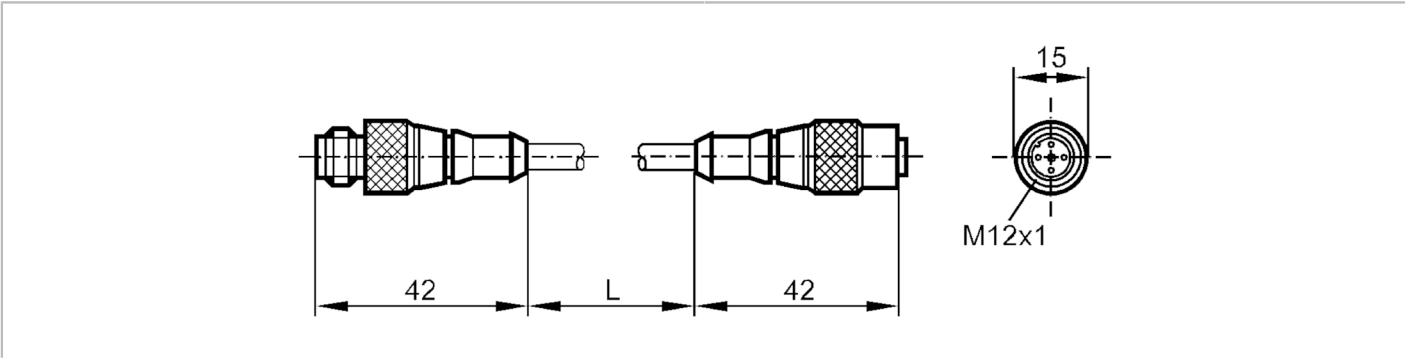

Electrical data		
Operating voltage	[V]	10...30 DC
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Dimensions	[mm]	15 x 15 x 42
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated

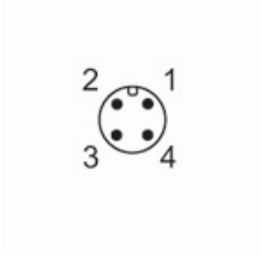

E10692




Connection cable

VDOGH040MSS00,6B04STGH040MSS

Electrical connection

Cable: 0.6 m, PUR, orange, Ø 5 mm; 4 x 0.25 mm² (128 x Ø 0.05 mm)

Connection

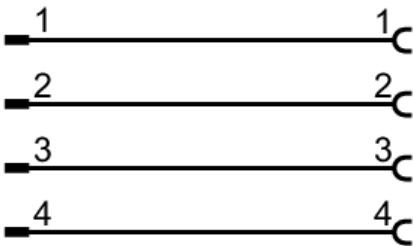

Electrical connection - Socket

Connector: 1 x M12, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated

