


E10712



Female cordset

ADOGF030ZDS0010A03

Article no longer available - archive entry

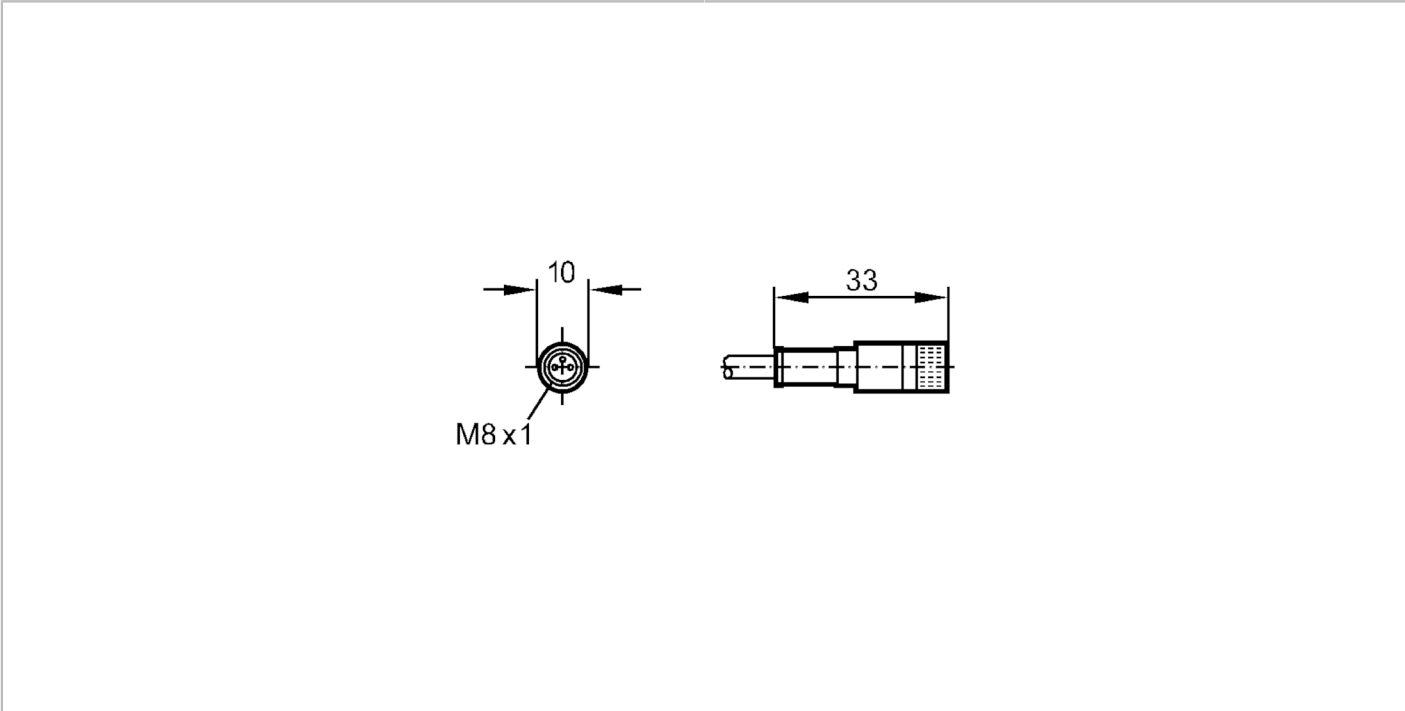

Electrical data

Operating voltage	[V]	< 60 AC/DC
-------------------	-----	------------

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 68

Mechanical data

Dimensions	[mm]	10 x 10 x 33
Material		PUR
Molded-body material		PUR
Material nut		diecast zinc

Remarks


Pack quantity		1 pcs.
---------------	--	--------

Electrical connection

Cable: 10 m, PUR / PVC, black, Ø 4.5 mm; 3 x 0.25 mm² (128 x Ø 0.05 mm)

Electrical connection - Socket

Connector: 1 x M8, straight; coding: A; Moulded body: PUR; Locking: diecast zinc

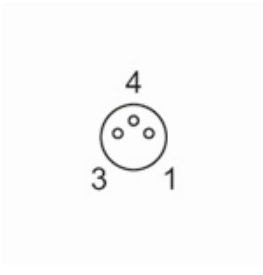


E10712



Female cordset

ADOGF030ZDS0010A03

Connection

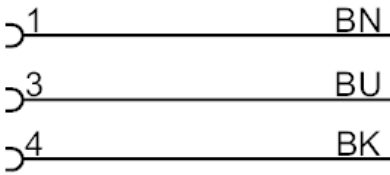

	Core colors :
BK =	black
BN =	brown
BU =	blue