

E10713




Female cordset

ADOAF030ZDS0005A03

Article no longer available - archive entry

Alternative articles: E11490
When selecting an alternative article and accessories please note that technical data may differ!

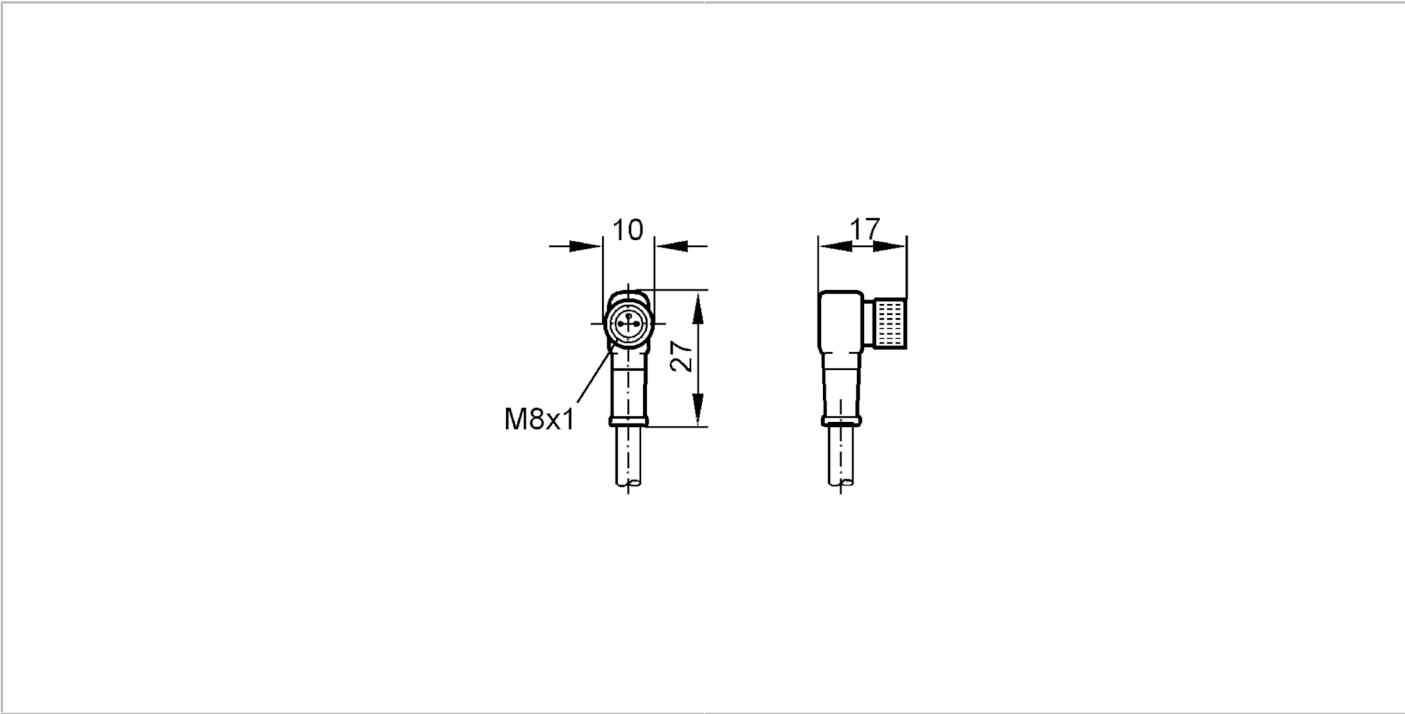

Electrical data		
Operating voltage	[V]	< 60 AC/DC
Protection class		III
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 68
Mechanical data		
Dimensions	[mm]	17 x 10 x 27
Material		PUR
Molded-body material		PUR
Material nut		diecast zinc
Remarks		
Pack quantity		1 pcs.

E10713



Female cordset


ADOAF030ZDS0005A03

Electrical connection

Cable: 5 m, PUR / PVC, black, Ø 4.5 mm; 3 x 0.25 mm² (128 x Ø 0.05 mm)

Electrical connection - Socket

Connector: 1 x M8, angled; coding: A; Moulded body: PUR; Locking: diecast zinc

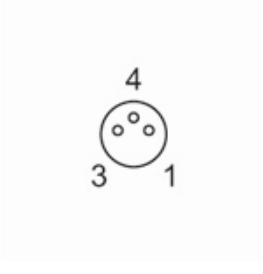

Connection



BN =	Core colors :
BK =	brown
BU =	black
	blue