

E10719



Female cordset

ADOAH042VAS0010A04

Article no longer available - archive entry



Electrical data

Operating voltage [V] 10...30 DC

Outputs

Electrical design PNP

Operating conditions

Ambient temperature [°C] -25...90

Protection IP 68

Mechanical data

Dimensions [mm] 36 x 15 x 26

Material PUR

Molded-body material PUR

Material nut stainless steel (1.4305 / 303)

Displays / operating elements

Display	Switching status	1 x LED, yellow
	Power	1 x LED, green

Remarks

Pack quantity 1 pcs.

E10719



Female cordset

ADOAH042VAS0010A04

Electrical connection


Cable: 10 m, PUR / PVC, black, Ø 4.5 mm; 4 x 0.34 mm² (182 x Ø 0.05 mm)

Electrical connection - Socket

Connector: 1 x M12, angled; coding: A; Moulded body: PUR; Locking: stainless steel (1.4305 / 303)



Connection

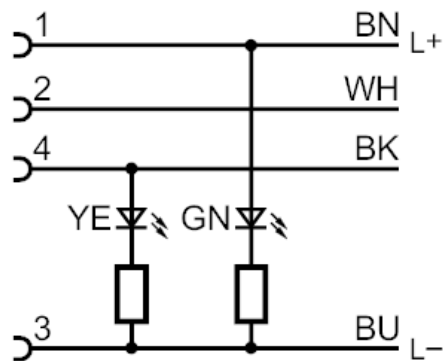

BK =	Core colors :
BN =	black
BU =	brown
WH =	blue
	white