

E10721




Female cordset

ADOAH042VAS0005A03

Article no longer available - archive entry

Alternative articles: EVC008

When selecting an alternative article and accessories please note that technical data may differ!

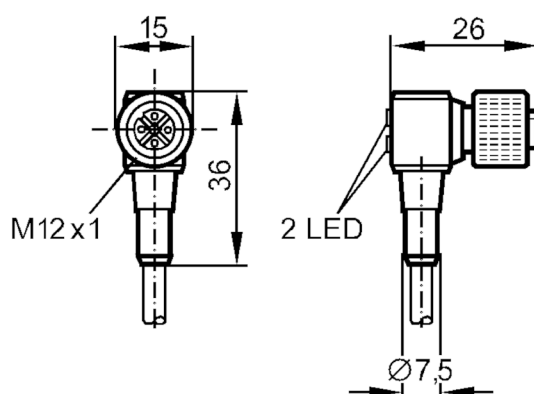

Electrical data

Operating voltage [V] 10...30 DC

Outputs

Electrical design PNP

Operating conditions

Ambient temperature [°C] -25...90

Protection IP 68

Mechanical data

Dimensions [mm] 36 x 15 x 26

Material PUR

Molded-body material PUR

Material nut stainless steel (1.4305 / 303)

Displays / operating elements

Display	Switching status	1 x LED, yellow
	Power	1 x LED, green

Remarks

Pack quantity 1 pcs.

E10721



Female cordset

ADOAH042VAS0005A03

Electrical connection

Cable: 5 m, PUR / PVC, black, Ø 4.5 mm; 3 x 0.34 mm² (182 x Ø 0.05 mm)

Electrical connection - Socket

Connector: 1 x M12, angled; coding: A; Moulded body: PUR; Locking: stainless steel (1.4305 / 303)



Connection



BK = Core colors :
BN = black
BU = brown
BU = blue