

E10724




Female cordset

ADOGH040VAS0005A04

Article no longer available - archive entry

Alternative articles: EVC002
When selecting an alternative article and accessories please note that technical data may differ!

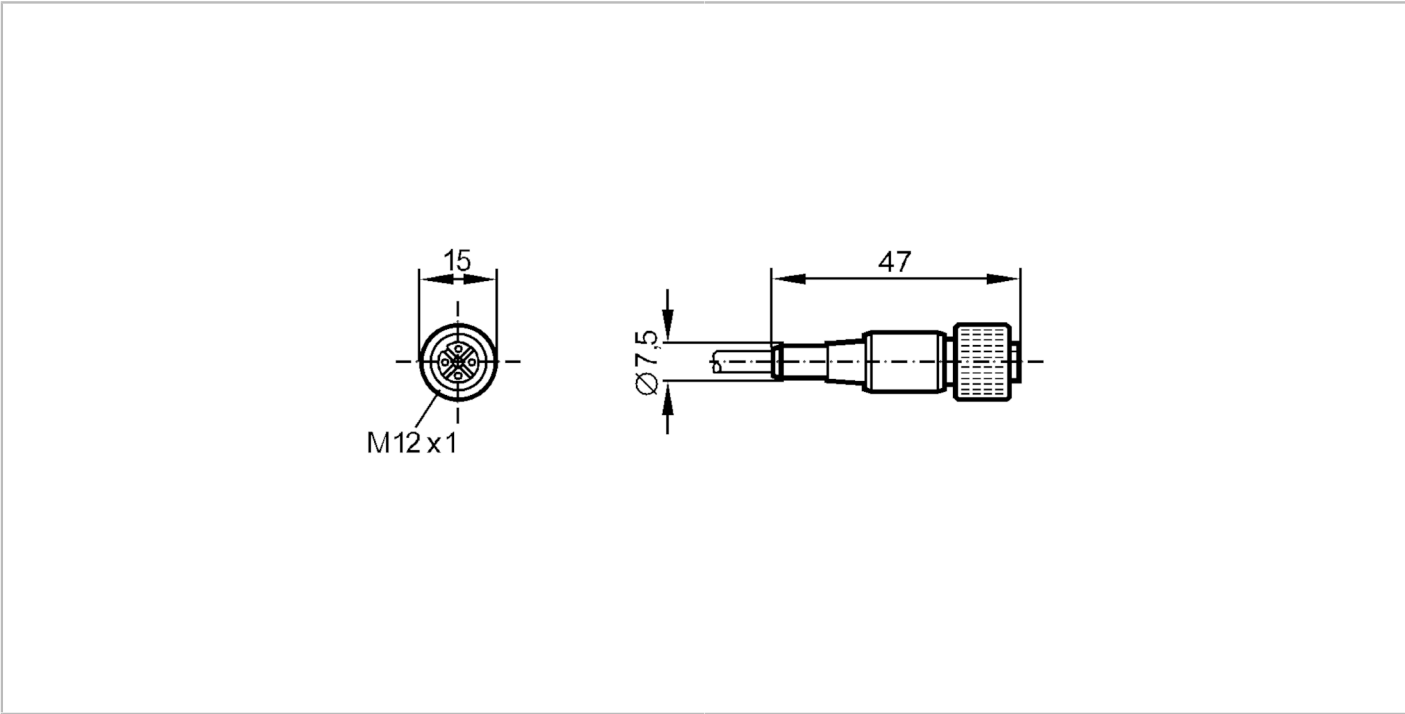

Electrical data		
Operating voltage	[V]	< 250 AC/DC
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Dimensions	[mm]	15 x 15 x 47
Material		PUR
Molded-body material		PUR
Material nut		stainless steel (1.4305 / 303)
Remarks		
Pack quantity		1 pcs.

E10724



Female cordset

ADOGH040VAS0005A04

Electrical connection


Cable: 5 m, PUR / PVC, black, Ø 4.5 mm; 4 x 0.34 mm² (182 x Ø 0.05 mm)

Electrical connection - Socket

Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: stainless steel (1.4305 / 303)



Connection

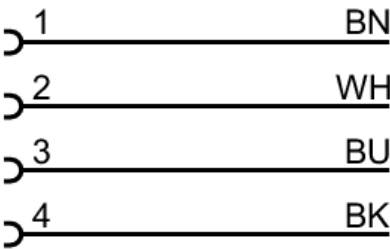

	Core colors :
BK =	black
BN =	brown
BU =	blue
WH =	white