

E10727




Female cordset

ADOAH040VAS0002A03

Article no longer available - archive entry

Alternative articles: EVC004

When selecting an alternative article and accessories please note that technical data may differ!

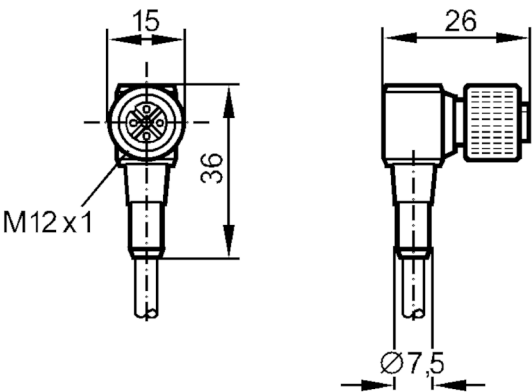

Electrical data

Operating voltage [V] < 60 AC/DC

Operating conditions

Ambient temperature [°C] -25...90

Protection IP 68

Mechanical data

Material PUR

Molded-body material PUR

Material nut stainless steel (1.4305 / 303)

Remarks

Pack quantity 1 pcs.

Electrical connection

Cable: 5 m, PVC, black, Ø 4.5 mm; 3 x 0.34 mm² (182 x Ø 0.05 mm)

Electrical connection - Socket

Connector: 1 x M12, angled; coding: A; Moulded body: PUR; Locking: stainless steel (1.4305 / 303)




E10727



Female cordset

ADOAH040VAS0002A03

Connection

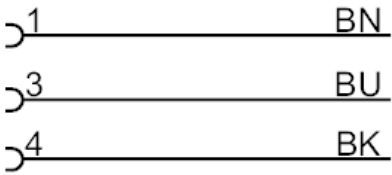

BK =	Core colors :
BN =	black
BU =	brown
	blue