


E10745



Female cordset

ADOAH040VAS0020E04

Article no longer available - archive entry

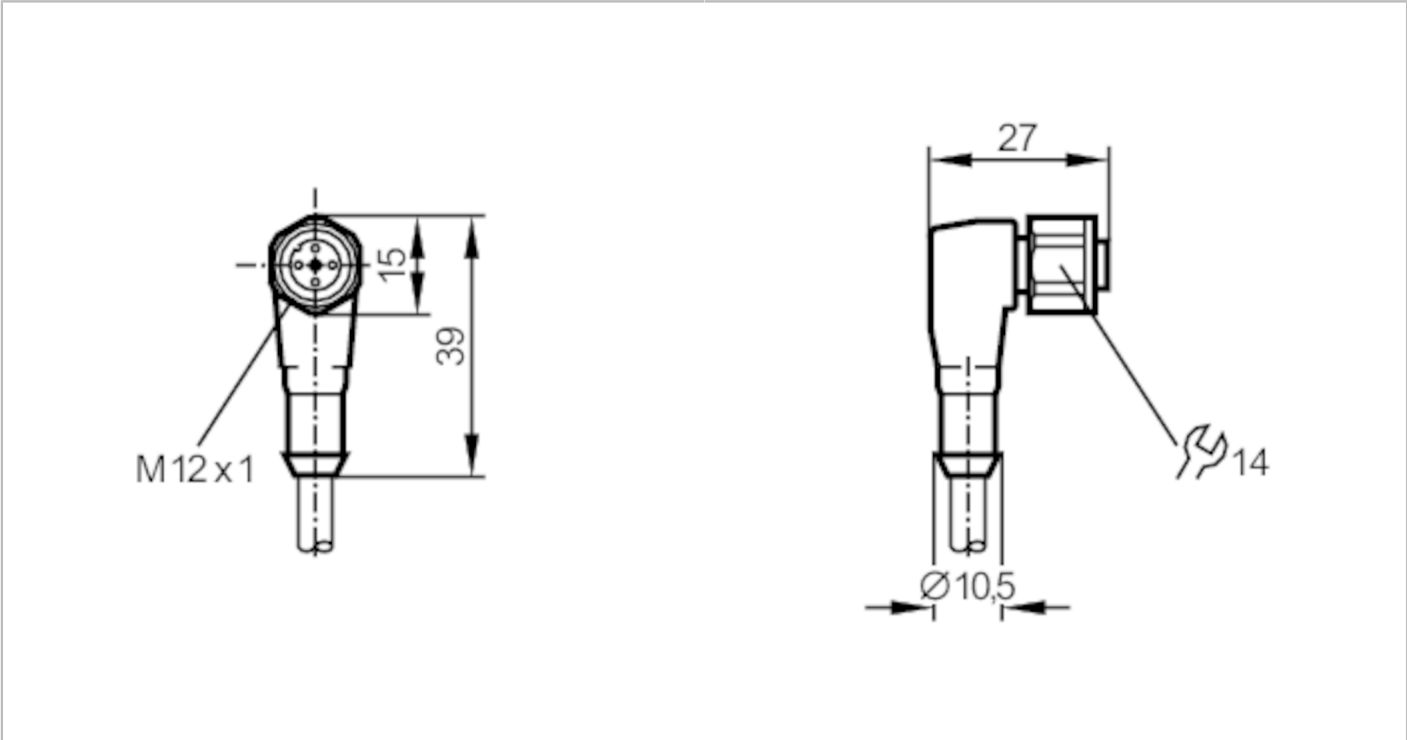

Application	
System	gold-plated contacts
Electrical data	
Operating voltage [V]	< 250 AC / < 300 DC
Operating conditions	
Ambient temperature [°C]	-25...70
Protection	IP 67
Mechanical data	
Dimensions [mm]	27 x 15 x 39
Material	PVC
Molded-body material	PVC
Material nut	stainless steel (1.4404 / 316L)
Remarks	
Pack quantity	1 pcs.

E10745



Female cordset

ADOAH040VAS0020E04

Electrical connection


Cable: 20 m, PVC, orange, Ø 5 mm; 4 x 0.25 mm² (32 x Ø 0.1 mm)

Electrical connection - Socket

Connector: 1 x M12, straight; coding: A; Moulded body: PVC; Locking: stainless steel (1.4404 / 316L); Contacts: gold-plated



Connection

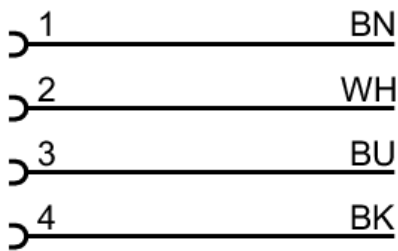

BK =	Core colors :
BN =	black
BU =	brown
WH =	blue
	white