


E10750



Damping magnet

MAGNET M2.0/ALNICO

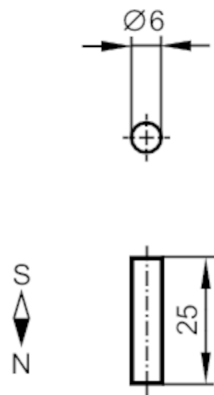

Operating conditions		
Ambient temperature	[°C]	-100...500
Mechanical data		
Weight	[g]	6.9
Dimensions	[mm]	Ø 6 / L = 25
Material		AlNiCo
Magnetic field strength	[mT]	110
Remarks		
Pack quantity		1 pcs.