


E10778



Connection cable

VDOAH040ZDS0003A03STGH040ZDS

Article no longer available - archive entry

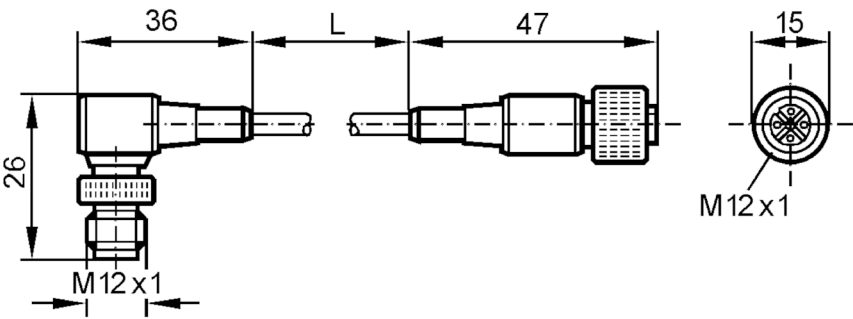

Electrical data

Operating voltage	[V]	< 250 AC/DC
-------------------	-----	-------------

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 68

Mechanical data

Material	PUR
Molded-body material	PUR
Material nut	ZnAl / Ni

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: ZnAl / Ni



E10778




Connection cable

VDOAH040ZDS0003A03STGH040ZDS

Electrical connection

Cable: 3 m, PUR / PVC, black; 4 x 0.34 mm² (182 x Ø 0.05 mm)

Connection

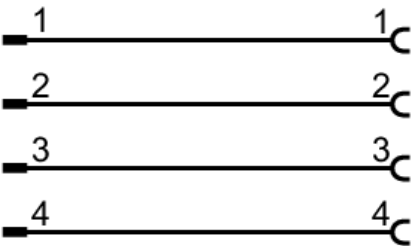

Electrical connection - Socket

Connector: 1 x M12, angled; coding: A; Moulded body: PUR; Locking: ZnAl / Ni

