


E10786



Female cordset

ADOGF030MSS0005E03

Article no longer available - archive entry

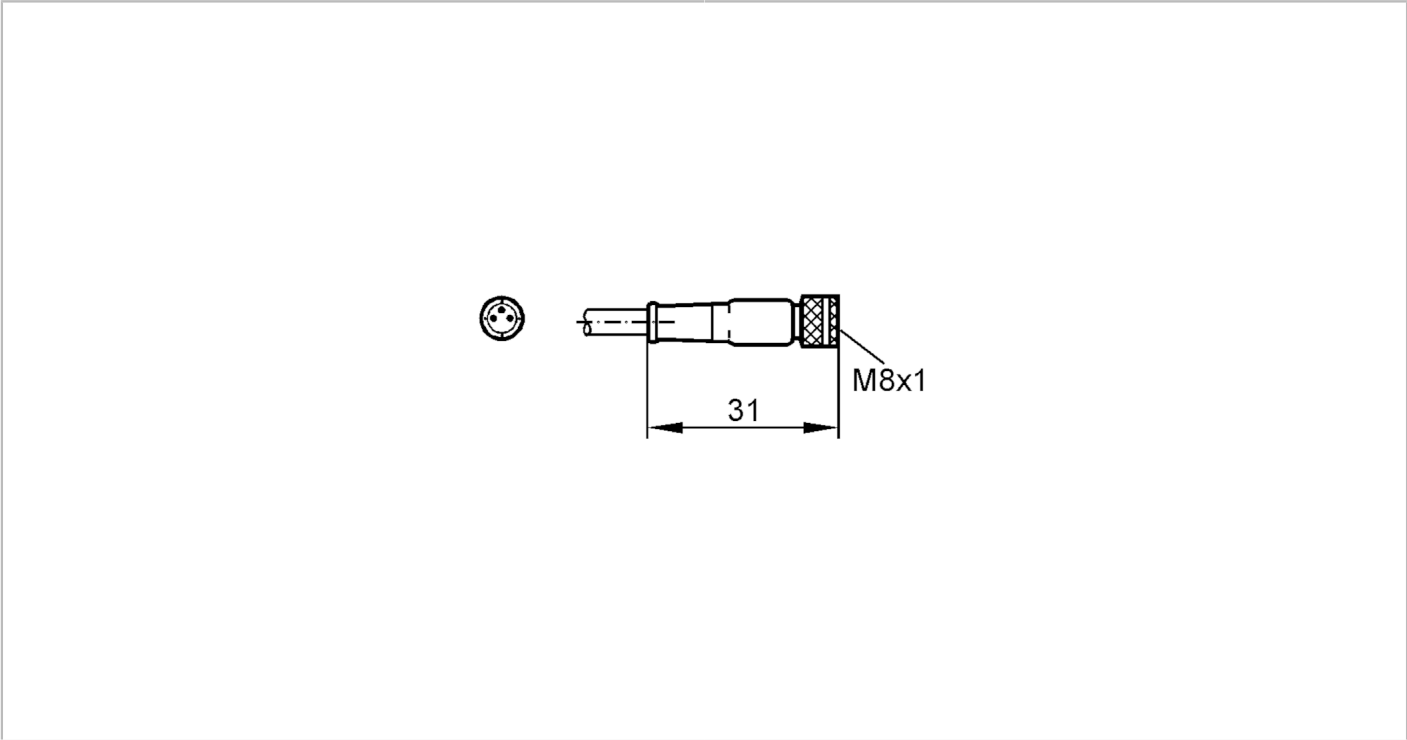

Electrical data		
Operating voltage	[V]	< 60 AC / < 75 DC
Protection class		III
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Material		TPU (urethane)
Molded-body material		TPU (urethane)
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.

E10786



Female cordset

ADOGF030MSS0005E03


Electrical connection

Cable: 5 m, PVC, orange, Ø 4.5 mm; 3 x 0.25 mm² (128 x Ø 0.05 mm)


Electrical connection - Socket

Connector: 1 x M8, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated

Connector: 1 x M8, straight; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated

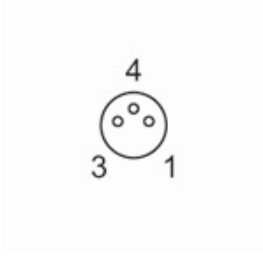

Connection

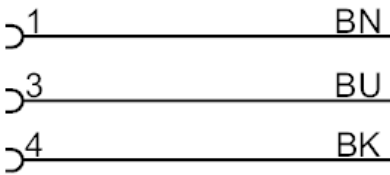

BK = Core colors :
BN = black
BU = brown
BK = blue