


E10787



Female cordset

ADOAF030MSS0005E03

Article no longer available - archive entry

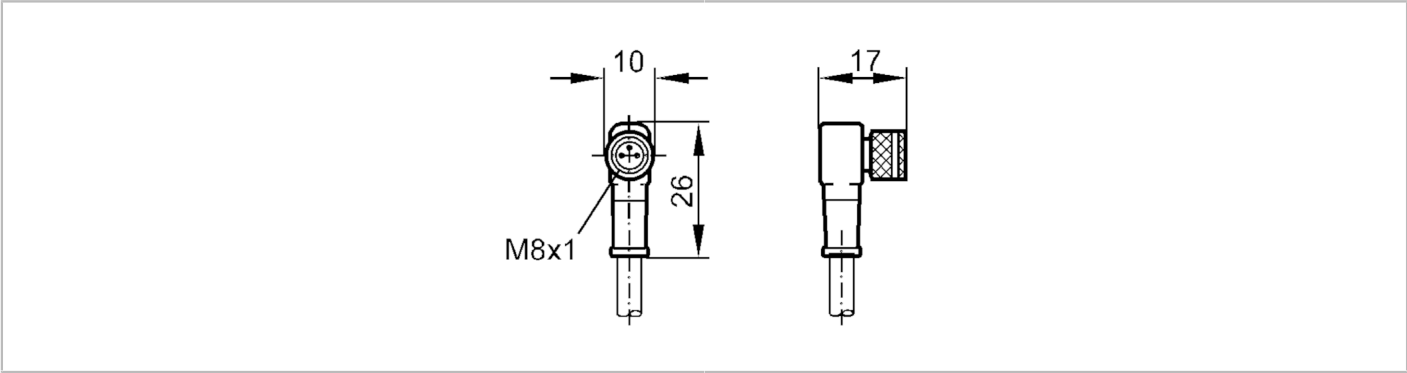

Electrical data

Operating voltage	[M]	< 60 AC / < 75 DC
Protection class		III

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 67

Mechanical data

Material	TPU (urethane)
Molded-body material	TPU (urethane)
Material nut	brass, nickel-plated

Remarks


Pack quantity	1 pcs.
---------------	--------

Electrical connection

Cable: 5 m, PVC, orange, Ø 4.5 mm; 3 x 0.25 mm² (128 x Ø 0.05 mm)

Electrical connection - Socket

Connector: 1 x M8, angled; coding: A; Moulded body: TPU (urethane); Locking: brass, nickel-plated

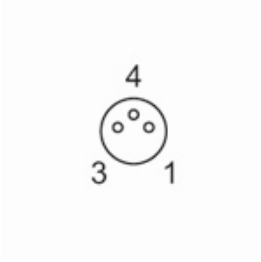


E10787



Female cordset

ADOAF030MSS0005E03

Connection

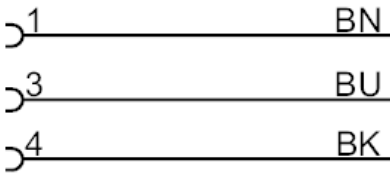

	Core colors :
BK =	black
BN =	brown
BU =	blue